


982A06RX

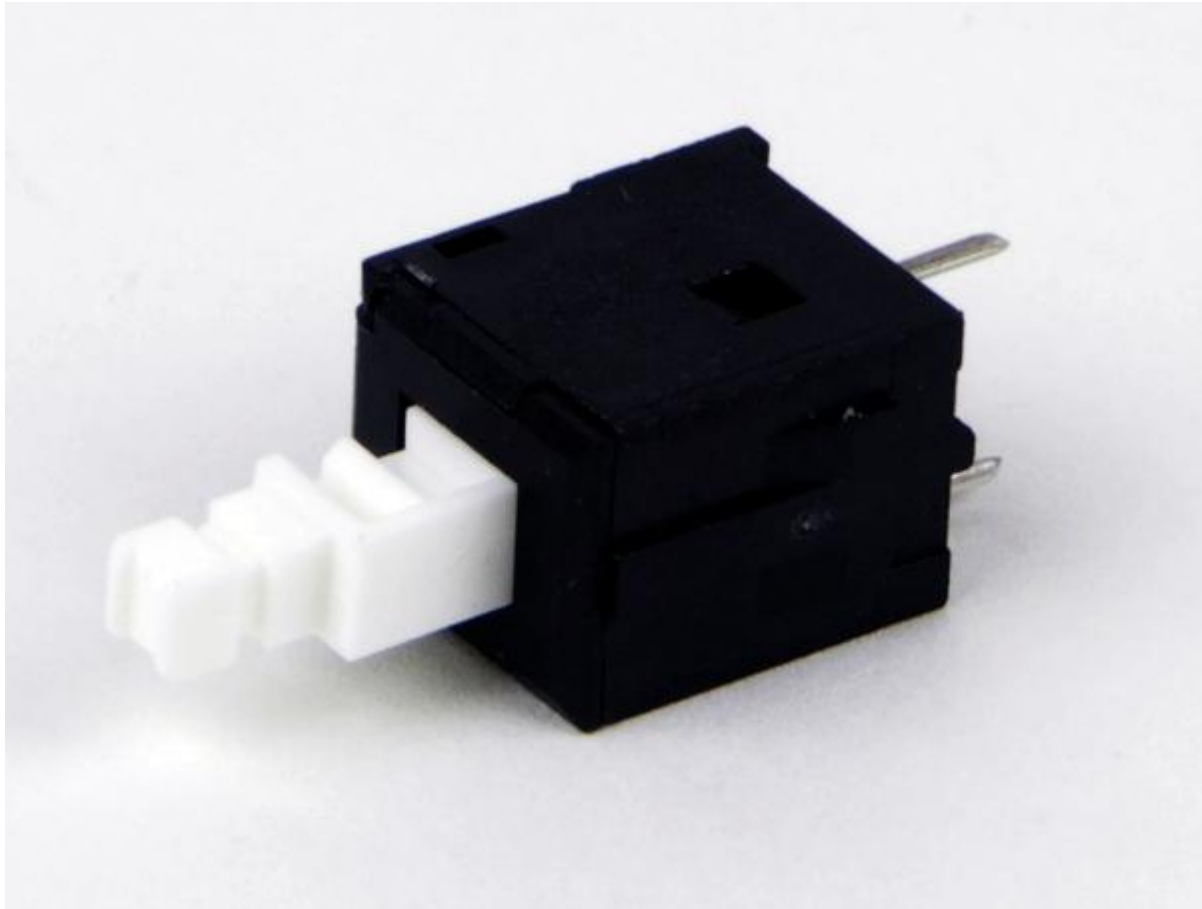

Switch Actuation: Momentary

Plunger Travel: .144 inch (3.66 mm)

Actuation Force (Full Travel): 12-15 ounce (340-425 grams)

Life: 1 million operations

ELECTRICAL

UL approved at .25 A @ 28V DC and .125 A @ 125V AC

MATERIALS

Housing: Molded thermoplastic UL 94V-0

Plunger: Molded thermoplastic UL 94V-0

Contactors: Copper alloy

Terminals: Copper alloy, solder-plated

Contact Surfaces: Gold-plated

MOUNTING

Switches have .157 inch (4 mm) long PC terminals for mounting on single- or double-sided PC boards up to .094 inch (2.4 mm) thick on 0.394 inch (10 mm) minimum centers in rows or arrays. 0.394 inch (10 mm) PC terminals available on special order. Rugged molded-in standoff legs provide stable mounting and clearance for PC board cleaning.

Drawings

http://www.switchcraft.com/Drawings/982a0_rx_cd_series.pdf