


Product number: 037171

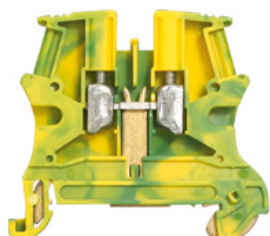

Description:

Brand:

Legrand

Series:

Viking3 klemmenstroken

Product Class:

Aardrijgklem

Price (per 1 st):

Start Date:

1-1-2014

Discount Group:

L5

Net Weight (kg):

0,012

Features

Connectable conductor cross section fine-strand without cable (mm²):	0.25 - 4	Connectable conductor cross section fine-strand with cable (mm²):	0.25 - 4
Connectable conductor cross section solid-core (mm²):	0.25 - 6	Type of electrical connection 1:	Screw connection
Type of electrical connection 2:	Screw connection	Connection position:	Sideways
Number of levels:	1	Number of clamp positions per level:	2
Mounting method:	DIN rail (top hat rail) 35 mm	Material insulation body:	Other
Operation temperature (°C):	-30 - 100	Inflammability class of insulation material acc. with UL94:	V2
Width/grid dimension (mm):	6	Colour:	Green-yellow
Height (mm):	48.6	Depth (mm):	49.4
Material:	Plastic	Surface treatment:	Polyamide

Prices are valid for the Dutch market. All prices are gross, excluding VAT. Technical and / or price changes and mistakes are possible.