

# WorkForce WF-2650DWF



Small business and home office users should look no further than the compact 4-in-1. The WF-2650DWF boasts double-sided, business quality printing and individual inks for cost savings. It also features Wi-Fi and Wi-Fi Direct® and is compatible with Epson Connect<sup>1</sup> to ensure quick and easy mobile printing.

## Business quality

This 4-in-1 printer uses a PrecisionCore printhead to ensure top quality, laser-like performance. Fast print speeds and a 30-page automatic document feeder for multi-page, 1200dpi scanning, copying and faxing offer the ultimate in convenience. Wi-Fi and Wi-Fi Direct® connectivity ensure the flexibility every small business needs.

## Low running costs

The WF-2650DWF uses Epson's 16 series inks, available in a choice of standard or XL cartridges sizes to suit your specific printing needs. XL inks can help you to reduce your printing costs by up to 25%<sup>2</sup>. The use of individual ink cartridges means only the colour used will need to be replaced, further reducing costs.

## Mobile printing


Epson Connect compatibility offers useful features like scan-to-cloud, email print and the Epson iPrint app<sup>1</sup>. The WF-2650DWF is also compatible with Apple AirPrint<sup>3</sup> and Google Cloud print, letting you print seamlessly from smartphones and tablets.

## DATASHEET



## KEY FEATURES

- **Business quality duplex printing**  
Laser-like results
- **4-in-1**  
Scan, copy, print and fax
- **Wi-Fi & Wi-Fi Direct**  
Print wirelessly wherever you are
- **Save money with individual inks**  
Only replace the colour used
- **Easy to use**  
150 page front-loading paper tray

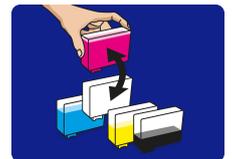

## PRODUCT SPECIFICATIONS

TECHNOLOGY	
Printing Method	PrecisionCore™ Print Head
Minimum Droplet Size	3.3 pl, With Variable-Sized Droplet Technology
Ink Technology	DURABrite™ Ultra
Nozzle Configuration	400 Nozzles black, 128 Nozzles per colour
Category	Office
All-in-One Functions	Print, Scan, Copy, Fax

PRINT	
Printing Speed ISO/IEC 24734	13 Pages/min Monochrome, 7.3 Pages/min Color
Maximum Printing Speed	20 Pages/min Color (plain paper), 33 Pages/min Monochrome (plain paper)
Duplex Printing Speed	6.5 A4 Pages/min Monochrome, 4.5 A4 Pages/min Color
ISO/IEC 24734	
Printing Resolution	4,800 x 1,200 dpi
Max Duty cycle	3,000 Pages per month
Colours	Magenta, Yellow, Cyan, Black
For detailed information on printing speeds please visit <a href="http://www.epson.eu/testing">http://www.epson.eu/testing</a> .	

SCAN	
Scanning Resolution	1,200 dpi x 2,400 dpi (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)
Single-sided scan speed (A4 black)	3 ipm with ADF scan 200 dpi (flatbed) 12 sec. with flatbed scan; 200 dpi (with ADF)
Single-sided scan speed (A4 colour)	3 ipm with ADF scan 200 dpi (flatbed) 27 sec. with flatbed scan; 200 dpi (with ADF)

FAX	
Fax speed dials (max)	60 names and numbers
Page memory	Up to 100 pages (ITU-T No.1 chart)
Fax Functions	PC Fax, Memory Reception, Auto Redial, Speed Dial
Type of fax	Walk-up black and white and colour fax capability
Fax Transmission Speed	Up to 33.6kbps / Approx. 3 sec/page
Error correction mode	CCITU/ITU Group3 fax with Error Correction Mode

PAPER / MEDIA HANDLING	
Paper Formats	A4, A5, A6, B5, C4 (Envelope), C6 (Envelope), DL (Envelope), No. 10 (Envelope)
Automatic Document Feeder	30 Pages

OTHER	
Warranty	12 months Carry in Optional warranty extension available

## LOGISTICS INFORMATION

SKU	C11CD77401
EAN code	8715946540085
Dimensions Single Carton	485 x 435 x 300 mm
Carton Weight	8.46 Kg
Multiple Order Quantity	1 Units
Country of Origin	Indonesia
Pallet Size Euro	14 Units
Pallet Size Block	28 Units



For more information please contact:

Telephone: 01952 607111 (UK)+  
01 436 7742 (Republic of Ireland)  
E-mail: [enquiries@epson.co.uk](mailto:enquiries@epson.co.uk)  
Chat: [etalk.epson-europe.com](http://etalk.epson-europe.com)  
Fax: 0871 222 6740  
+ Local call rate.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

## WorkForce WF-2650DWF

### WHAT'S IN THE BOX

- Main unit
- Individual Ink Cartridges
- Driver and utilities (CD)
- Warranty document
- User manual (CD)
- Software (CD)
- Quick Start Guide
- Power cable

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

	Pen and crossword 16	Pen and crossword 16XL
●	175 pages*	500 pages*
● ● ● ●	165 pages*	450 pages*

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. Epson iPrint requires a wireless connection and the Epson printing app. Email print and scan-to-cloud require an internet connection. For more information, supported languages and devices, please visit [www.epsonconnect.eu](http://www.epsonconnect.eu). Comparison based on the cost per page for 16 vs. 16XL inks 3. AirPrint-enabled printers work with iPad (all models), iPhone (3GS or later), and iPod touch (3rd generation or later) running the latest version of iOS. 4. Automatic set-up compatible with Windows 8, Windows 7, Windows Vista and Mac OS

**EPSON®**