



600X600 BACKLIT LED PANEL - VALUE  
4PACK

**LD4PAN3653V-2**

36 W - 3600lm - 4000K

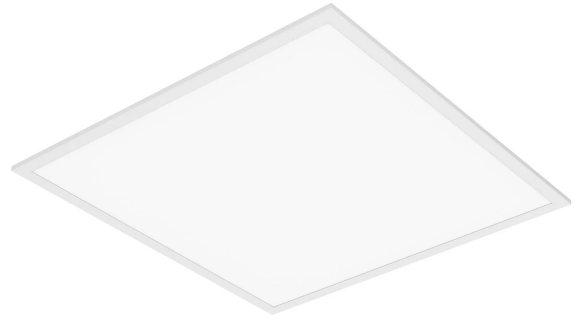

DIMENSIONS	A	B	C
1	30	595	595

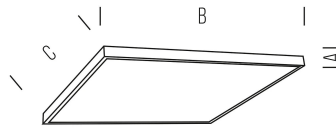

GENERAL INFORMATIONS	
Code	LD4PAN3653V-2
Ean	8031453033316
Family	600X600 BACKLIT LED PANEL - VALUE 4PACK
Product line	PAN
Technology	LED
Operating temperature (° C)	-10 - +40
Years warranty	3
(RAL) Colour	9003
External driver	SI
Replaceable source	NO

LIGHTING DATA	
Light colour	CW
CCT (K)	4000
Luminous flux (lm)	3600
Luminous Flux Module (lm)	4100
Beam (°)	120
Color rendering (CRI)	>80

TECHNICAL FEATURES	
Power (W)	36
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50/60
Insulation class	2
Power factor	>0,90
Dimmer compatibility	NO
Nominal life (h)	35000

PACKAGING	
Packaging	BOX
Pack	1 / 1

## 600X600 BACKLIT LED PANEL - VALUE 4PACK

### **LD4PAN3653V-2**

36W-3600lm-4000K

- Backlit LED panel, LGP not required
- IP40 front / IP20 rear protection
- RAL9016 white painted finish aluminium frame
- Optional: DALI-Push dimmable driver
- Optional: emergency kit with DC connector
- Optional: surface mounting, suspension or recessed KIT
- Pack of 4 panels (1 piece corresponds to 4 panels)

