


8161

Lifting web slings, orange, 10t two-layer flat sling, 20t four-layer flat sling, reinforced eyes

CE

EN 1492-1

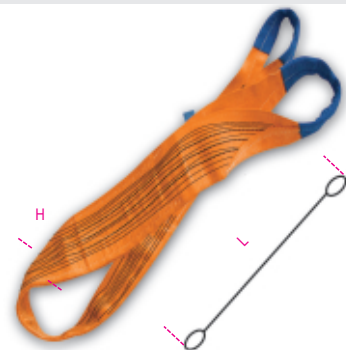

	art.	L m	H mm	WLL ton
081610030	8161 3-T10	3	300	10
081610040	8161 4-T10	4	300	10
081610050	8161 5-T10	5	300	10
081610060	8161 6-T10	6	300	10
081610080	8161 8-T10	8	300	10
081610100	8161 10-T10	10	300	10
081610120	8161 12-T10	12	300	10
081612030	8161 3-T20	3	300	20
081612040	8161 4-T20	4	300	20
081612050	8161 5-T20	5	300	20
081612060	8161 6-T20	6	300	20
081612080	8161 8-T20	8	300	20
081612100	8161 10-T20	10	300	20
081612120	8161 12-T20	12	300	20