

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731120430](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Stamped Contact, Male, Crimp, 0.10µm Gold Plating, 20-24 AWG

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	D-Sub Products
Series	173112
Comments	Packaging Detail: 10 strips of 25 pieces in a box
Contact Type	Stamped Crimp
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Type	Standard Density
UPC	191128225908

Physical


Durability (mating cycles max)	50
Gender	Male
Material - Contact	Copper Alloy
Net Weight	0.100/g
Orientation	Straight
Packaging Type	Carton
Plating - Contact	Gold over Nickel
Plating min - Mating	0.100µm
Temperature Range - Operating	-55° to +125°C
Termination Style	Crimp
Wire Size AWG	20, 22, 24

Electrical

Current - Maximum per Contact	5.0A
-------------------------------	------

Material Info

Engineering Number	P7L
--------------------	-----

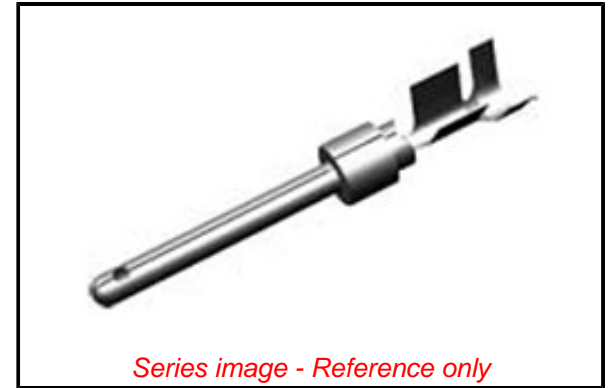

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[173112 Series](#)

Use With

FCT Standard-Density Connectors