


Model 300 1/2", N·m/lbf·ft, 'Industrial' Mushroom Ratchet

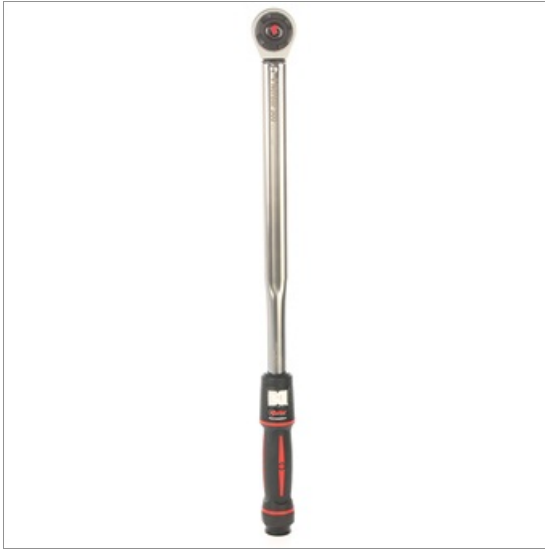

The New Professional torque wrench has been re-engineered to be even more accurate, durable and easy to use.

The square drive features a finger grip on the top ('mushroom' head) that assists with running down the nut until resistance is met.

Part number: 15005

EAN Bar Code: 5060207564298

NATO number: 5120-99-7944365

Accuracy: $\pm 3\%$

Operates between:

60.0 - 300.0 N·m

45.0 - 220.0 lbf·ft



TECHNICAL SPECIFICATIONS

- Length: 593 mm
- Square Size: 1/2"
- Weight: 1.42 Kg
- Ratchet Teeth: 60
- Ratchet Type: Industrial 'Mushroom' head
- Ratchet Diameter: 51 mm
- Packed Length: 730 mm
- Packed Weight: 2.17 Kg

FEATURES

- Factory calibrated to $\pm 3\%$ and our new mechanism ensures that the accuracy is retained for longer.
- Every wrench is supplied with a calibration certificate
- Ergonomic new handle with a high proportion of soft-feel, high grip material.
- Handle material and lens resist all chemicals in common automotive, industrial and aviation use.
- Secure push/pull locking mechanism is quick and intuitive to use and prevents accidental adjustment.
- Large scale window and long scale length for great visibility and accurate setting.
- Unique on a torque wrench, the TimeStrip[®] gives a visual indication that the wrench is due for re-calibration.