


Item number: 56257

# One Piece Shovel, D Grip, 1040 mm, Orange

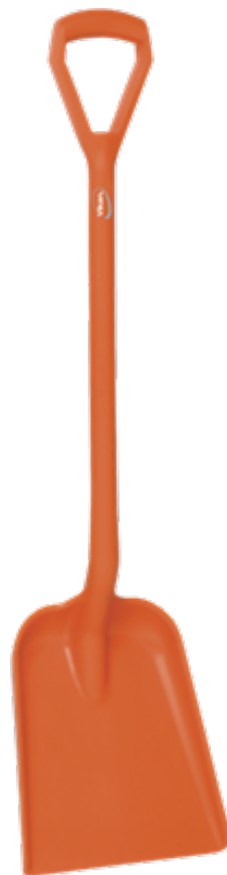

Lightweight and durable shovel. Its one piece construction eliminates areas where bacteria can be harboured. Smooth surface makes it extremely easy to clean, ideal for use in food production areas for moving food ingredients or large quantities of food waste.

# Technical data

<b>EAN Number</b>	5705020562570
<b>DUN Number</b>	15705020562577
<b>Commodity Code</b>	39241000
<b>FDA compliant raw material (21)</b>	Yes
<b>Glass &amp; Fork (EU 1935/2004), Declaration of Compliance, Regulation (EU) No 10/2011</b>	Yes
<b>Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice</b>	Yes
<b>Use of Phthalates &amp; Bisphenol A</b>	No
<b>Material</b>	Polypropylene
<b>Shovel Blade Size, L x W</b>	327 x 271 mm
<b>Box Quantity</b>	5 Pcs.
<b>Quantity per Pallet (80 x 120 x 200 cm)</b>	75 Pcs.
<b>Colour</b>	Orange
<b>Height</b>	120 mm
<b>Length</b>	1040 mm
<b>Width</b>	271 mm
<b>Box Length</b>	1190 mm
<b>Box Height</b>	365 mm
<b>Box Width</b>	265 mm
<b>Gross Weight</b>	1.455 kg.
<b>Net Weight</b>	1.26 kg
<b>Country of origin</b>	Denmark
<b>Max cleaning temperature (Autoclave)</b>	121 °Celsius
<b>Max. cleaning temperature (Dishwasher)</b>	93 °Celsius
<b>Max. usage temperature (for food contact)</b>	80 °Celsius
<b>Max usage temperature (non food contact)</b>	100 °Celsius
<b>Min. usage temperature</b>	-20 °Celsius
<b>Max. drying temperature</b>	120 °Celsius
<b>Min. pH-value in usage concentration</b>	2
<b>Max. pH-value in Usage Concentration</b>	10.5

New equipment should be cleaned, disinfected and sterilised, as appropriate to its intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.