

**POLYPRO®**, Type 4X

**POLYPRO®**, Type 4X



**Industry Standards**

Mounting brackets required to meet UL/CSA external mounting requirements.

UL 508A Listed; Type 4, 4X, 12, 13; File No. E61997  
 cUL Listed per CSA C22.2 No 94; Type 4, 4X, 12, 13; File No. E61997  
 Enclosure flammability evaluated per UL 508A  
 Window flammability evaluated per UL 508A

NEMA/EEMAC Type 4, 4X, 12, 13  
 CSA File No. 42186; Type 4, 4X, 12, 13 (solid covers only)  
 IEC 60529, IP66

**Application**

POLYPRO® polyester enclosures perform exceptionally well in applications where harsh chemicals, weather extremes and corrosive environments demand toughness from a lightweight enclosure. Providing excellent ultraviolet protection and a tight environmental seal, these versatile, feature-rich enclosures are also recyclable.

**Specifications**

- Non-glass-filled polyester material offers superior UV resistance; eliminates fiberbloom associated with fiberglass
- Provides excellent chemical resistance to a broad range of solvents, alkalis and acids
- Resists cracking and provides excellent impact resistance
- Lighter-weight than fiberglass
- Recyclable
- Easy, dustless in-field modifications using standard tools
- Overlapping tongue-and-groove raised cover and gasket provide a secure Type 4X seal

- Removable snap-hinge cover allows for easy access to cover and body for modifications
- Molded layout grid on inside of body and solid covers assists with component mounting
- Molded-in embosses for rear panel mounting
- Optional cover screws included with all models
- Internal rail system and adjustable panel blocks allow for panel height adjustment and installation of multiple panels
- Scratch-resistant polycarbonate windows
- Standard models include body and cover, two mounting feet, two latch assemblies with optional cover screws and hardware (adjustable panel blocks and panels sold separately)

**Finish**

RAL 7035 light-gray textured finish inside and out

**Accessories**

*See also Accessories.*  
 Adjustable Panel Block Kit  
 Panels for Junction Boxes  
 HOL-SEALERS™ Non-Metallic Hole Seals  
 Aluminum Swing-Out Panels  
 Stainless Steel Latches (Padlockable)  
 Hinge Retainers

**Modification and Customization**

Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.


Bulletin: PCR

# POLYPRO®, Type 4X

## Standard Product

Catalog Number	AxBxCin./mm	Door Type	Aluminum Panel	Panel Size		F in./mm	G in./mm	H in./mm	J in./mm	L in./mm	M in./mm	N in./mm	W in./mm
				D x E in./mm	F in./mm								
A644PHC	6.12 x 4.12 x 4.38	Solid	A6P4AL	4.88 x 2.88	4.32	7.38	2.56	3.91	8.15	—	—	5.23	
	155 x 105 x 111			124 x 73	110	187	65	99	207	—	—	133	
A644PHCW	6.12 x 4.12 x 4.38	Window	A6P4AL	4.88 x 2.88	4.32	7.38	2.56	3.91	8.15	4.25	2.25	5.23	
	155 x 105 x 111			124 x 73	110	187	65	99	207	108	57	133	
A664PHC	6.12 x 6.12 x 4.38	Solid	A6P6AL	4.88 x 4.88	4.32	7.38	4.56	3.91	8.15	—	—	7.23	
	155 x 155 x 111			124 x 124	110	187	116	99	207	—	—	184	
A664PHCW	6.12 x 6.12 x 4.38	Window	A6P6AL	4.88 x 4.88	4.32	7.38	4.56	3.91	8.15	4.25	4.25	7.23	
	155 x 155 x 111			124 x 124	110	187	116	99	207	108	108	184	
A864PHC	8.12 x 6.12 x 4.38	Solid	A8P6AL	6.75 x 4.88	4.32	9.38	4.56	3.91	10.15	—	—	7.23	
	206 x 155 x 111			171 x 124	110	238	116	99	258	—	—	184	
A864PHCW	8.12 x 6.12 x 4.38	Window	A8P6AL	6.75 x 4.88	4.32	9.38	4.56	3.91	10.15	6.25	4.25	7.23	
	206 x 155 x 111			171 x 124	110	238	116	99	258	159	108	184	
A884PHC	8.12 x 8.12 x 4.38	Solid	A8P8AL	6.75 x 6.88	4.32	9.38	6.56	3.91	10.15	—	—	9.23	
	206 x 206 x 111			171 x 175	110	238	167	99	258	—	—	234	
A884PHCW	8.12 x 8.12 x 4.38	Window	A8P8AL	6.75 x 6.88	4.32	9.38	6.56	3.91	10.15	6.25	6.25	9.23	
	206 x 206 x 111			171 x 175	110	238	167	99	258	159	159	234	
A1084PHC	10.12 x 8.12 x 4.38	Solid	A10P8AL	8.75 x 6.88	4.32	11.38	6.56	3.91	12.15	—	—	9.23	
	257 x 155 x 111			222 x 175	110	289	167	99	309	—	—	234	
A1084PHCW	10.12 x 8.12 x 4.38	Window	A10P8AL	8.75 x 6.88	4.32	11.38	6.56	3.91	12.15	8.25	6.25	9.23	
	257 x 155 x 111			222 x 175	110	289	167	99	309	210	159	234	
A10106PHC	10.04 x 10.04 x 6.38	Solid	A10P10AL	8.75 x 8.88	6.32	11.31	8.56	5.91	12.08	—	—	11.23	
	255 x 255 x 162			222 x 226	161	287	217	150	307	—	—	285	
A10106PHCW	10.04 x 10.04 x 6.38	Window	A10P10AL	8.75 x 8.88	6.32	11.31	8.56	5.91	12.08	8.25	8.25	11.23	
	255 x 255 x 162			222 x 226	161	287	217	150	307	210	210	285	
A12106PHC	12.08 x 10.09 x 6.38	Solid	A12P10AL	10.75 x 8.88	6.32	13.34	8.56	5.91	14.08	—	—	11.23	
	307 x 256 x 162			273 x 226	161	339	217	150	358	—	—	285	
A12106PHCW	12.08 x 10.09 x 6.38	Window	A12P10AL	10.75 x 8.88	6.32	13.34	8.56	5.91	14.08	10.25	8.25	11.23	
	307 x 256 x 162			273 x 226	161	339	217	150	358	260	210	285	
A14128PHC	14.02 x 12.01 x 8.35	Solid	A14P12AL	12.75 x 10.88	8.27	15.27	10.56	7.91	16.04	—	—	13.32	
	356 x 305 x 212			324 x 276	210	388	268	201	407	—	—	338	
A14128PHCW	14.02 x 12.01 x 8.35	Window	A14P12AL	12.75 x 10.88	8.27	15.27	10.56	7.91	16.04	12.25	10.25	13.32	
	356 x 305 x 212			324 x 276	210	388	268	201	407	311	260	338	
A16148PHC	16.02 x 14.01 x 8.35	Solid	A16P14AL	14.75 x 12.88	8.27	17.27	12.56	7.91	18.04	—	—	15.32	
	407 x 356 x 212			375 x 327	210	439	319	201	458	—	—	389	
A16148PHCW	16.02 x 14.01 x 8.35	Window	A16P14AL	14.75 x 12.88	8.27	17.27	12.56	7.91	18.04	14.25	12.25	15.32	
	407 x 356 x 212			375 x 327	210	439	319	201	458	362	311	389	
A181610PHC	17.95 x 15.94 x 10.35	Solid	A18P16AL	16.75 x 14.88	10.27	19.20	14.56	9.91	19.97	—	—	17.32	
	456 x 405 x 263			425 x 378	261	488	370	252	507	—	—	440	
A181610PHCW	17.95 x 15.94 x 10.35	Window	A18P16AL	16.75 x 14.88	10.27	19.20	14.56	9.91	19.97	16.25	14.25	17.32	
	456 x 405 x 263			425 x 378	261	488	370	252	507	413	362	440	

Purchase panels separately. Panels are available in aluminum, mild steel, stainless steel, conductive and composite materials.

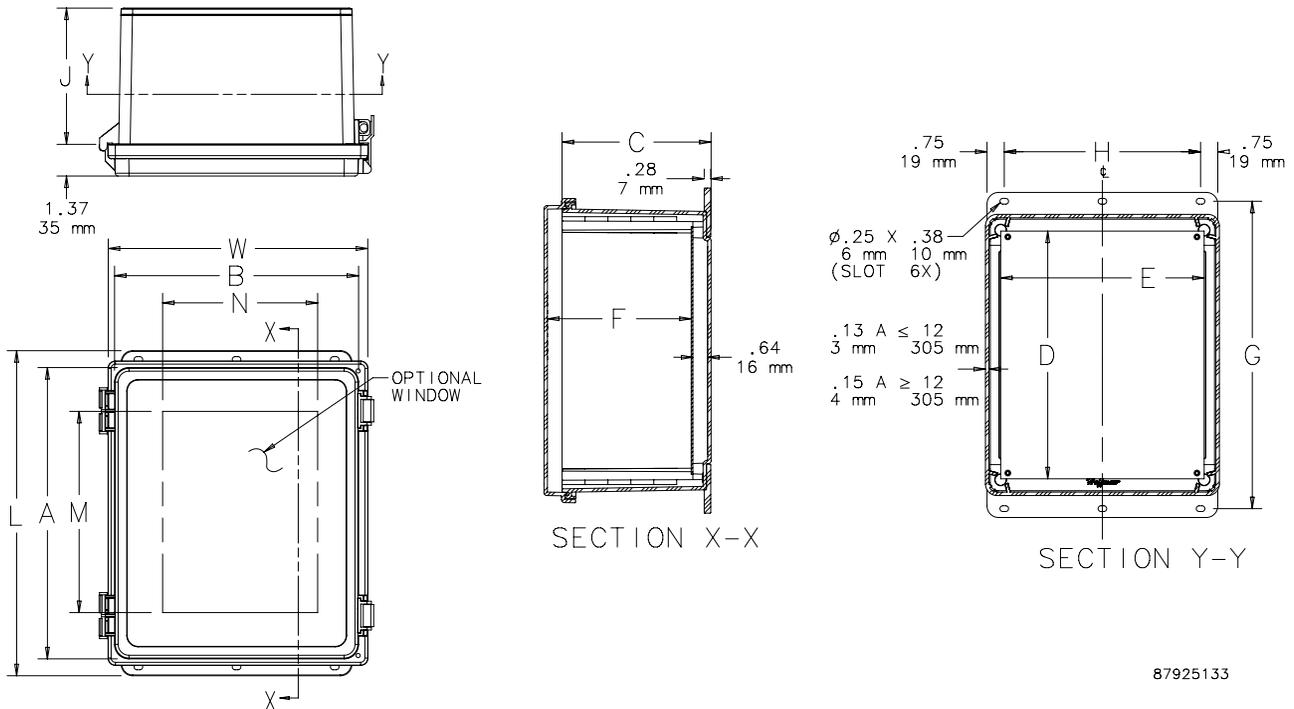

87925133

**POLYPRO® , Type 4X**


**Adjustable Panel Block Kit**

Panel blocks slide inside POLYPRO internal rail system for panel height adjustment within top 5 in. of enclosure. Allows for installation of multiple panels.

Bulletin: PCRY

Catalog Number	Qty.
APNLBLK	4

Includes Allen wrench

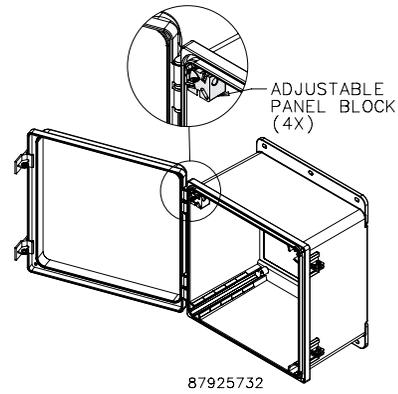


87925732

**Polyester Mounting Bracket Kits**

Replacement POLYPRO mounting brackets are sold in sets of two and include hardware for mounting to enclosure. Included with standard POLYPRO models.

Bulletin: PCRY

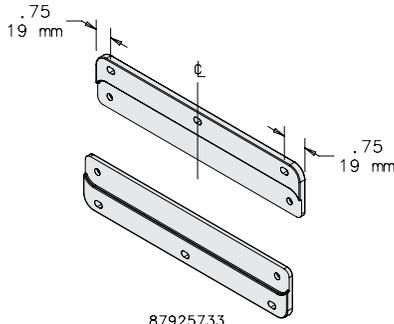


87925733

Catalog Number	Description (in.)	Qty.
APOLYFT4	4.00	2
APOLYFT6	6.00	2
APOLYFT8	8.00	2
APOLYFT10	10.00	2
APOLYFT12	12.00	2
APOLYFT14	14.00	2
APOLYFT16	16.00	2

**Aluminum Swing-Out Panels**

Includes four POLYPRO Adjustable Panel Blocks. No enclosure modification is required for installation.

Bulletin: PCRY

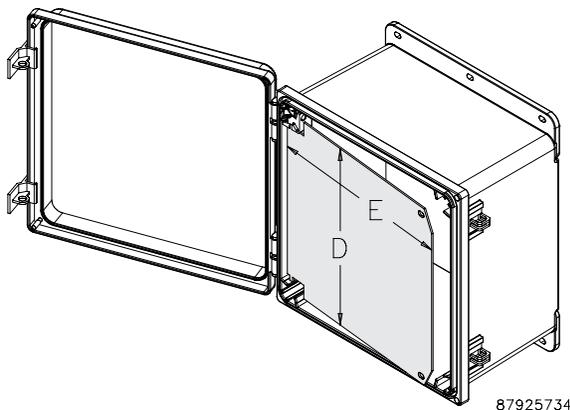

87925734

Catalog Number	D x E (in.)	D x E (mm)
A64PSWPNL	5.00 x 3.62	127 x 92
A66PSWPNL	5.00 x 5.62	127 x 143
A86PSWPNL	7.00 x 5.62	178 x 143
A88PSWPNL	7.00 x 7.62	178 x 194
A108PSWPNL	9.00 x 7.62	229 x 194
A1010PSWPNL	9.00 x 9.62	229 x 244
A1210PSWPNL	11.00 x 9.62	279 x 244
A1412PSWPNL	13.00 x 11.62	330 x 295
A1614PSWPNL	15.00 x 13.62	381 x 346
A1816PSWPNL	17.00 x 15.62	432 x 397

**POLYPRO®, Type 4X**

**Stainless Steel Latches (Padlockable)**



Stainless Steel Latches can be retrofitted on all POLYPRO models with no modification or drilling required. Hinge/latch constructed of corrosion-resistant polyester with a Type 316L stainless steel bail. Included with standard POLYPRO models.

Bulletin: PCRY

Catalog Number	Qty.
AQRLSS6	2

**Hinge Retainers**



Hinge Retainers can be field-installed without modification to POLYPRO hinges for applications where easy cover removal is not desired. Two retainers per enclosure is recommended. Kit includes ten hinge retainers.

Catalog Number	Description	Pkg. Qty.
AHGCLP	POLYPRO Hinge Retainers	10