


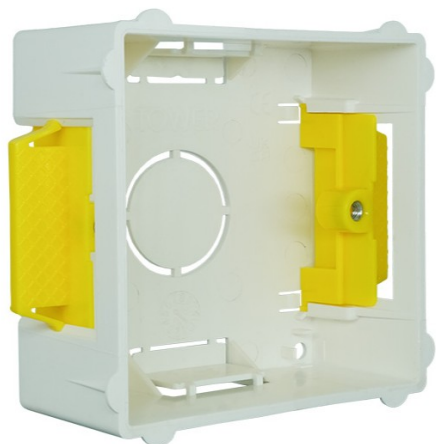

1g 35mm Lipless Dry Lining Box

Description

Lipless Dry lining back box suitable for flush mounting of 1 gang flat plate wiring accessories.

Features

- Unique Lipless design suitable for flush mounting flat plate accessories
- Pivoting fast fit lugs aid installation
- Manufactured from flame-retardant polypropylene
- Top, bottom and rear cable entries
- Suitable for plaster board thickness of 7mm – 30mm

Product Code

1g 35mm Lipless Dry Lining Box TDL3591

Technical Specification

- **External Dimensions (W x H x Dmm)** - 82 x 82 x 36mm (± 1mm)
- **Internal Dimensions (W x H x Dmm)** - 69.5 x 69.5 x 34.5mm (± 1mm)
- **No. of Gangs** - 1
- **Colour** - White Box – RAL9010, Yellow Lugs – RAL1018
- **Knockouts** - Top and bottom slots. 25mm diameter circular knockout in rear.
- **Type of Mounting** - Flush
- **Material** - Flame Retardant Polypropylene

Compliance

- BS 4662
- BS EN 60670-1