
 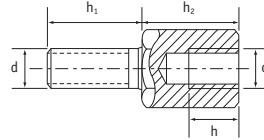


Hex Spacer - Male/Female

SR2702

Nickel Plated Brass/Zinc Plated Steel/Stainless Steel

- Screw-in design



Richco

Part Number			Dimensions						Std Pack Qty
Nickel Plated Brass	Zinc Plated Steel	Stainless Steel	d	S	h2	h1	h		
304105040050	-	304105041556	M2	4	5	6	3	100	
304108040050	-	304108041556	M2	4	8	6	4	100	
304110040050	-	304110041556	M2	4	10	6	6	100	
304112040050	-	-	M2	4	12	6	6	100	
304115040050	-	304115041556	M2	4	15	6	6	100	
304118040050	-	-	M2	4	18	6	6	100	
304120040050	-	304120041556	M2	4	20	6	6	100	
304125040050	-	-	M2	4	25	6	6	50	
304130040050	-	-	M2	4	30	6	6	50	
304205040050	-	304205041556	M2.5	5	5	6	3	100	
304206040050	-	-	M2.5	5	6	6	3	100	
304207040050	-	-	M2.5	5	7	6	4	100	
304208040050	-	304208041556	M2.5	5	8	6	4	100	
304210040050	-	304210041556	M2.5	5	10	6	6	100	
304211040050	-	-	M2.5	5	11	6	6	100	
304212040050	-	304212041556	M2.5	5	12	6	6	100	
304215040050	-	304215041556	M2.5	5	15	6	6	100	
304218040050	-	304218041556	M2.5	5	18	6	6	100	
304220040050	-	304220041556	M2.5	5	20	6	6	100	
304225040050	-	-	M2.5	5	25	6	6	100	
304230040050	-	-	M2.5	5	30	6	6	100	
304305040050	304305041152	-	M3	5	5	8	3	100	
304306040050	304306041152	-	M3	5	6	8	3	100	
304307040050	304307041152	-	M3	5	7	8	4	100	
304308040050	304308041152	-	M3	5	8	8	4	100	
304309040050	-	-	M3	5	9	8	4	100	
304310040050	304310041152	-	M3	5	10	8	6	100	
304311040050	-	-	M3	5	11	8	6	100	
304312040050	304312041152	-	M3	5	12	8	8	100	
304313040050	-	-	M3	5	13	8	8	100	
304314040050	-	-	M3	5	14	8	8	100	
304315040050	304315041152	-	M3	5	15	8	8	100	
304316040050	-	-	M3	5	16	8	8	100	
304317040050	-	-	M3	5	17	8	8	100	
304318040050	304318041152	-	M3	5	18	8	8	100	
304320040050	304320041152	-	M3	5	20	8	8	100	
304325040050	304325041152	-	M3	5	25	10	10	100	
304330040050	304330041152	-	M3	5	30	10	10	100	
304335040050	304335041152	-	M3	5	35	10	10	100	
304340040050	304340041152	-	M3	5	40	10	10	50	
304345040050	304345041152	-	M3	5	45	10	10	50	
304350040050	304350041152	-	M3	5	50	10	10	50	
304355040050	-	-	M3	5	55	10	10	50	
304360040050	304360041152	-	M3	5	60	10	10	50	
304305240050	-	-	M3	5.5	5	6	3	100	
304305140050	304305141152	304305141556	M3	5.5	5	8	3	100	
304306240050	-	-	M3	5.5	6	6	3	100	
304306140050	-	-	M3	5.5	6	8	3	100	
304308240050	-	-	M3	5.5	8	6	4	100	
304308140050	304308141152	304308141556	M3	5.5	8	8	4	100	
304310240050	-	-	M3	5.5	10	6	6	100	
304310140050	304310141152	304310141556	M3	5.5	10	8	6	100	
304312240050	-	-	M3	5.5	12	6	6	100	
304312140050	304312141152	304312141556	M3	5.5	12	8	8	100	
304313140050	-	-	M3	5.5	13	8	8	100	
304315240050	-	-	M3	5.5	15	6	6	100	
304315140050	304315141152	304315141556	M3	5.5	15	8	8	100	
304318240050	-	-	M3	5.5	18	6	6	100	
304318140050	304318141152	304318141556	M3	5.5	18	8	8	100	
304320240050	-	-	M3	5.5	20	6	6	100	
304320140050	304320141152	304320141556	M3	5.5	20	8	8	100	
304325240050	-	-	M3	5.5	25	6	6	100	
304325140050	304325141152	304325141556	M3	5.5	25	10	10	100	
304330240050	-	-	M3	5.5	30	6	6	100	

Part Number			Dimensions						Std Pack Qty
Nickel Plated Brass	Zinc Plated Steel	Stainless Steel	d	S	h2	h1	h		
304330140050	304330141152	304330141556	M3	5.5	30	10	10	100	
304335240050	-	-	M3	5.5	35	6	6	50	
304335140050	304335141152	-	M3	5.5	35	10	10	50	
304340240050	-	-	M3	5.5	40	6	6	50	
304340140050	304340141152	304340141556	M3	5.5	40	10	10	50	
304350240050	-	-	M3	5.5	50	6	6	50	
304350140050	304350141152	304350141556	M3	5.5	50	10	10	50	
304360140050	304360141152	-	M3	5.5	60	10	10	50	
304408040050	304408041152	-	M4	7	8	8	4	100	
304410040050	304410041152	304410041556	M4	7	10	8	6	100	
304412040050	304412041152	-	M4	7	12	8	8	100	
304415040050	304415041152	304415041556	M4	7	15	8	8	100	
304418040050	304418041152	-	M4	7	18	8	8	100	
304420040050	304420041152	304420041556	M4	7	20	8	8	100	
304425040050	304425041152	304425041556	M4	7	25	10	10	50	
304430040050	304430041152	304430041556	M4	7	30	10	10	50	
304435040050	304435041152	-	M4	7	35	10	10	50	
304440040050	304440041152	304440041556	M4	7	40	10	10	50	
304445040050	304445041152	-	M4	7	45	10	10	50	
304450040050	304450041152	304450041556	M4	7	50	10	10	50	
-	304455041152	-	M4	7	55	10	10	50	
304460040050	304460041152	-	M4	7	60	10	10	25	
-	304465041152	-	M4	7	65	10	10	25	
304470040050	304470041152	-	M4	7	70	10	10	25	
-	304480041152	-	M4	7	80	10	10	25	
304510040050	304510041152	304510041556	M5	8	10	8	6	50	
304512040050	304512041152	304512041556	M5	8	12	8	8	50	
304515040050	304515041152	304515041556	M5	8	15	8	8	50	
304518040050	304518041152	304518041556	M5	8	18	8	8	50	
304520040050	304520041152	304520041556	M5	8	20	8	8	50	
304525040050	304525041152	304525041556	M5	8	25	10	10	50	
304530040050	304530041152	304530041556	M5	8	30	10	10	50	
304535040050	304535041152	304535041556	M5	8	35	10	10	25	
304540040050	304540041152	304540041556	M5	8	40	10	10	25	
304545040050	304545041152	-	M5	8	45	10	10	25	
304550040050	304550041152	304550041556	M5	8	50	10	10	25	
-	304555041152	-	M5	8	55	10	10	25	
304560040050	304560041152	304560041556	M5	8	60	10	10	25	
-	304570041152	304570041556	M5	8	70	10	10	25	
-	304610341152	304610341556	M6	10	10	12	6	50	
-	304612341152	304612341556	M6	10	12	12	8	50	
-	304615341152	304615341556	M6	10	15	12	8	50	
-	-	304618341556	M6	10	18	12	8	50	
-	304618341152	-	M6	10	18	12	12	50	
-	304620341152	304620341556	M6	10	20	12	12	50	
-	304625341152	304625341556	M6	10	25	12	13	50	
-	304630341152	304630341556	M6	10	30	12	13	25	
-	304635341152	304635341556	M6	10	35	12	13	25	
-	304640341152	304640341556	M6	10	40	12	13	25	
-	304650341152	304650341556	M6	10	50	12	13	25	
-	304660341152	304660341556	M6	10	60	12	13	25	
-	304670341152	304670341556	M6	10	70	12	13	25	
-	304680341152	304680341556	M6	10	80	12	13	25	
-	304690341152	304690341556	M6	10	90	12	13	25	
-	304815041152	-	M8	13	15	14	8	10	
-	304818041152	-	M8	13	18	14	12	10	
-	304820041152	-	M8	13	20	14	12	10	
-	304825041152	-	M8	13	25	14	15	10	
-	304830041152	-	M8	13	30	14	15	10	
-	304835041152	-	M8	13	35	14	15	10	
-	304840041152	-	M8	13	40	14	15	10	
-	304850041152	-	M8	13	50	14	15	10	
-	304860041152	-	M8	13	60	14	15	10	
-	304870041152	-	M8	13	70	14	15	10	