

特点

- 铸铁台钳结构
- 钢钳口
- 360° 旋转台钳头
- g 形夹附件

RS Pro x 30mm 65mm x 60mm 、 2.1kg

RS 号: 752-2428



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与领先品牌相当的质量、而无需支付高昂的价格。

商品描述属性 1

RS Pro zhie 台钳特别适用于通用应用、安装在旋转平台上、可进行 360° 调整。此台钳由高级铸铁制成、具有可调 g 形夹、用于连接到表面。这种易于夹紧的操作意味着台钳高度便携且用途广泛。固定基座和坚固的夹持钳口可在专业应用中实现完全的信心。

一般规格

虎钳类型	g 形夹钳
应用	木材工人和木匠、工程师和金属工人、机械工、业余爱好者和业余爱好者

机械规格

钳口开度	60mm
钳口宽度	65mm
钳口深度	30mm
钳口高度容量	30mm
旋转虎钳头	360°
安装	夹式
重量	2.1Kg



Order Code	Manufacturers Code	Description
752-2428	52-192-875	G-Clamp Vice


Maximum Jaw Opening	60mm
Jaw Width	65mm
Jaw Height	30mm
Maximum Table Clamping	40mm
Rotating Vice Head	360°
Flat Anvil Size	30 x 40mm
Vice Head Material	Cast Iron
Table Clamp Material	Cast Iron
Vice Guide Rods	Steel
Vice Jaw Material	Steel
Weight	2.1K

1	Vice Jaws
2	Vice Handle
3	Swivelling Vice Head
4	Table / Bench Clamp Bracket
5	Clamp Screw
6	Swivel Lock
7	Flat Anvil



This lightweight portable mini vice is suitable for use in engineering, automotive and home workshops and can be easily mounted to any convenient working surface

Maximum Jaw Opening	60mm
Jaw Width	65mm
Jaw Height	30mm
Maximum Table Clamping	40mm
Rotating Vice Head	360°

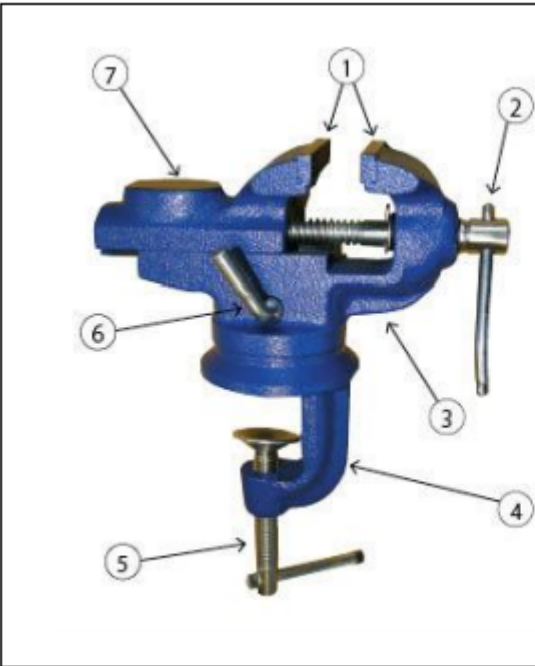

Maximum Jaw Opening	60mm
Jaw Width	65mm
Jaw Height	30mm
Maximum Table Clamping	40mm
Rotating Vice Head	360°
Flat Anvil Size	30 x 40mm
Vice Head Material	Cast Iron
Table Clamp Material	Cast Iron
Vice Guide Rods	Steel
Vice Jaw Material	Steel
Weight	2.1K

1	Vice Jaws
2	Vice Handle
3	Swivelling Vice Head
4	Table / Bench Clamp Bracket
5	Clamp Screw
6	Swivel Lock
7	Flat Anvil