


C4AT, Film, Metallized Polypropylene, Power, 1.5 uF, 5%, 250 VAC, 400 VDC, 70°C, Lead Spacing = 27.5mm

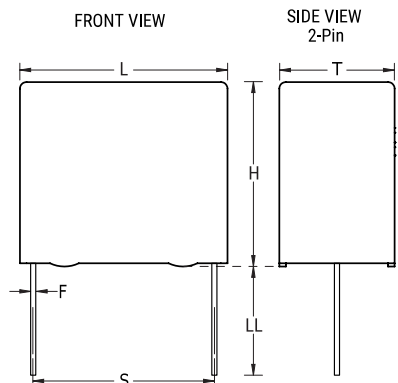

Dimensions

L	32mm NOM
H	20mm NOM
T	10mm NOM
S	27.5mm +/-0.4mm
LL	6mm -2mm
F	1.2mm NOM

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	288

General Information

Supplier:	KEMET
Series:	C4AT
Dielectric:	Metallized Polypropylene
Style:	Radial
Features:	Switching
RoHS:	Yes
Lead:	Wire Leads

Specifications

Capacitance:	1.5 uF
Capacitance Tolerance:	5%
Voltage AC:	250 VAC
Voltage DC:	400 VDC
Temperature Range:	-40/+85C
Rated Temperature:	70°C
Dissipation Factor:	0.05%
Max dV/dt:	74 V/us
Resistance:	7.1 mOhms (100kHz)
Ripple Current:	10 Amps (100kHz 70C), 111 Amps (Peak)