

## FEATURES

- Strong
- Heavy duty with reinforced base, sides and stacking rim
- Resistant to most industrial solvents
- Hygienic, clean, smooth inside faces guard against build-up of grease etc
- Available in 7 sizes and 6 colours as standard
- Index card slot for instant product identification

## RS PRO PP Storage Bin Storage Bin, 130mm x 205mm, Yellow

RS Stock No.: 484-4113



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

From RS Pro range of high-quality plastic storage bins made from robust polypropylene designed for simple and effective small parts organisation and storage in the workplace and in the home. These storage bins are stackable and can be stacked on top of one another to provide both a space saving solution to your storage needs and ease of handling.

### General Specifications

<b>Material</b>	PP
<b>Colour</b>	Yellow
<b>Size</b>	Size 4
<b>Application</b>	Home, Office ,Warehouse ,Laboratory, Hospital, Garage

### Mechanical Specifications

<b>Volume</b>	9.1 litres
<b>Maximum Container Stack Height</b>	6mm
<b>Maximum Stack Load Capacity</b>	36kg
<b>Weight</b>	24kg

External dimensions		
<b>Dimension</b>	350mm x 205mm x 130mm	
<b>Depth</b>	350mm	(Overall)
<b>Width</b>	205mm	(Overall)
<b>Height</b>	130mm	(Overall)
<b>Base Length</b>	300mm	(Overall)


Internal dimensions	
<b>Dimension</b>	330mm x 179mm x 117mm
<b>Depth</b>	330mm
<b>Width</b>	179mm
<b>Height</b>	117mm
<b>Base Length</b>	287mm

## Operation Environment Specifications

Operating Temperature Range	-15°C to +50°C
-----------------------------	----------------

## Approvals

Compliance/Certifications	BS IEC 61340-5-1:2007
---------------------------	-----------------------

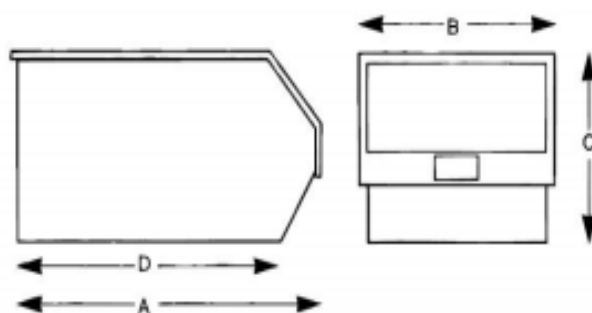

All Dimensions in mm	SIZE 1	SIZE 2	SIZE 3	SIZE 4	SIZE 5	SIZE 6	SIZE 7
(A) Overall Length	90	167	240	350	350	376	510
(B) Overall Width	100	101	150	205	205	419	315
(C) Overall Height	50	76	130	130	181	180	200
(D) Overall Base Length	64	143	200	300	300	310	450
(A) Internal Length	80	154	223	330	330	350	470
(B) Internal Width	88	88	128	179	177	378	270
(C) Internal Height	42	63	120	117	167	164	188
(D) Internal Base Length	65	131	188	287	287	295	435
Volumes (Litres)	0.46	1.27	4.6	9.1	12.8	28.3	31.4
Maximum Container Stack Height – (See Details Opposite)	7	5	4	6	4	8	6
Maximum Stack Load Capacity (kg)	12	12	30	36	45	60	42

Description	H x W x D (mm)	RS Stock Code / Colour							
		White	Blue	Red	Green	Yellow	Orange	Black Recycled	ESD Black
Size 1	50 x 100 x 90	315-1123	484-3996	484-3974	484-3980	484-3823	469-6728	909-6902	550-319
Size 2	75 x 100 x 165	315-1139	484-4028	484-4006	484-4012	484-3839	469-6784	909-6906	550-325
Size 3	132 x 150 x 240	315-1145	484-4056	484-4034	484-4040	484-4062	469-6778	909-6915	550-331
Size 4	132 x 205 x 350	315-1151	484-4107	484-4078	484-4090	484-4113	469-6762	909-6918	909-6928
Size 5	182 x 205 x 350	315-1173	484-4157	484-4129	484-4135	484-4163	469-6756	909-6912	909-6937
Size 6	182 x 420 x 375	315-1189	484-4185	484-3845	484-4179	484-4191	469-6740	909-6921	909-6930
Size 7	200 x 310 x 520	456-3426	350-5873	350-5845	350-5895	350-5867	469-5157	909-6924	Not Available
Clear Bin Front for Size 7		456-3432							