


Datasheet

Indoor/outdoor thermometer with hygrometer

Stock No:

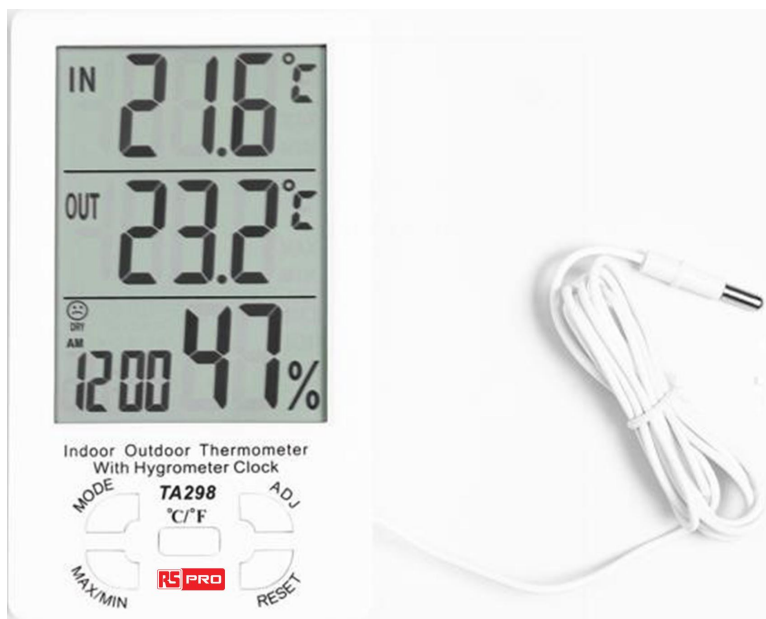

Technical Specifications:

Type	Parameters
Product length:	88 mm
Product wide:	25 mm
Product High:	150mm
Colour:	White
Weight:	205g

Product Introduction

This product is suitable for factories,warehouse,building air conditioning management, hospitals,aquaculture species,room,office,hotel,laboratory... Modern energy saving good helper. The machine can be hung on the wall or on the table,on the back there is a hook and bracket.

Features & Benefits:

- Temperature/humidity display.
- Celsius/Fahrenheit switch display.
- Simultaneous display of indoor/outdoor temperature.
- Maximum and minimum memory function.
- Power ultra-Low 1.5V Battery(No.7 Battery,No Battery)
- Size of LCD:66 / 92 mm
- Max outdoor temperature sensing distance:1.5M



Specifications

Range
Indoor Temperature Range: 0 to 50° C Outdoor Temperature Range: -40 to 70° C
Resolution
Humidity Resolution: 10%RH to 99%RH**
Precision
Humidity Precision: Plus/Minus 5% Accuracy Plus/Minus 1° C