

# HEX•PRO™

[www.bondhus.com/hex-pro/](http://www.bondhus.com/hex-pro/)


## Pivot Head Hex and TORX® Wrenches



Pivot Head Hex and TORX® wrenches allow tool users to insert wrench into socket head screw one time only, pivoting around obstacles.




Joints are engineered to be as small as possible without weakening the tool.

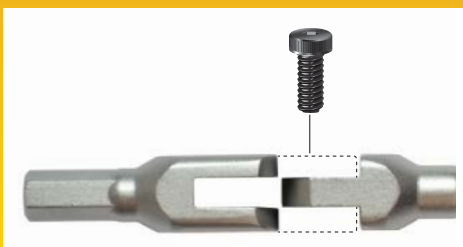

Forged hinges provide a simple, effective, patented design. Fewer pieces make Pivot Head Hex and TORX® wrenches stronger and less likely to break than competitors.

- Fits Inch and Metric Hex, TORX®, and Star screws
- Available in 25 sizes to cover most fastener heads
- Heat treated high quality industrial tool steel
- Long handles for extra reach
- Matte chrome finish to prevent corrosion
- Lifetime Warranty

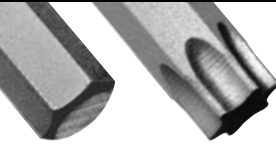

**BONDHUS**  
**LIFETIME WARRANTY**

HexPro™ tools are manufactured to the exacting specifications of Bondhus Corporation. If any HexPro™ tool breaks or fails to meet your expectations in any way, simply return it. We will replace it free of charge.

# HEX•PRO™

www.bondhus.com/hex-pro/

## Pivot Head Hex and TORX® Wrenches



Sets	PART#	PCS	CONTENTS	QTY
<b>Inch</b>	00033	5	1/8, 5/32, 3/16, 1/4, 5/16" - Bondhex Case	1
	00038	5	3/16, 7/32, 1/4, 5/16, 3/8" - Bondhex Case	1
<b>Metric</b>	00025	5	3, 4, 5, 6, 8mm - Bondhex Case	1
	00028	5	4, 5, 6, 8, 10mm - Bondhex Case	1
	00035	6	4, 5, 6, 7, 8, 10mm - Bondhex Case	1

Singles	SIZE	INCH		MM		PART#	QTY	TAGGED/BARCODED	
		INCH	MM	INCH	MM			PART#	QTY
<b>Inch</b>	1/8	4.0	102	1.01	26	88007	1	88707	1
	9/64	4.2	107	1.07	27	88008	1	88708	1
	5/32	4.2	108	1.09	28	88009	1	88709	1
	3/16	4.6	118	1.24	32	88010	1	88710	1
	7/32	4.8	123	1.32	33	88011	1	88711	1
	1/4	5.4	138	1.50	38	88012	1	88712	1
	5/16	6.4	162	1.75	44	88013	1	88713	1
	3/8	7.0	177	1.91	49	88014	1	88714	1
<b>Metric</b>	3	3.9	99	0.99	25	88056	1	88756	1
	4	4.2	107	1.22	31	88060	1	88760	1
	5	4.8	123	1.39	35	88064	1	88764	1
	6	5.5	140	1.60	41	88068	1	88768	1
	7	6.4	162	1.86	47	88070	1	88770	1
	8	6.4	162	1.86	47	88072	1	88772	1
	10	7.1	180	2.04	52	88076	1	88776	1

Sets	PART#	PCS	CONTENTS	QTY
<b>TORX®</b>	00023	5	T20, T25, T30, T40, T45 - Bondhex Case	1
	00039	5	T30, T40, T45, T47, T50 - Bondhex Case	1

Singles	SIZE	INCH		MM		PART#	QTY	TAGGED/BARCODED	
		INCH	MM	INCH	MM			PART#	QTY
<b>TORX®</b>	T15	3.2	82	1.22	31	88215	1	88715	1
	T20	3.2	82	1.22	31	88220	1	88720	1
	T25	3.6	92	1.39	35	88225	1	88725	1
	T27	3.6	92	1.39	35	88227	1	88727	1
	T30	3.6	92	1.39	35	88230	1	88730	1
	T40	4.2	107	1.60	41	88240	1	88740	1
	T45	4.9	124	1.86	47	88245	1	88745	1
	T47	4.9	124	1.86	47	88247	1	88747	1
	T50	4.9	124	1.86	47	88250	1	88750	1
	T55	5.4	138	2.04	52	88255	1	88755	1

Distributed by:

**Bondhus Corporation**  
 1400 E Broadway • PO Box 660  
 Monticello, MN 55362  
 Tel: 763-295-2162 • Toll Free: 800-328-8310  
 Fax: 763-295-4440

TORX® and TORX PLUS® are registered trademarks of Acument Intellectual Properties, LLC. HexPro is a trademark of Bondhus Corporation.