

AMP AMP Connect

MAIN MENU HELP
FAMILIES REGISTRATION

Alphabetical Picture Part Number
SEARCH SEARCH SEARCH

Go To Step Search™ Screen

350783-1 -- 1 of 1 products

Soft Shell Connectors


Soft Shell - Housings, Test Connectors and IDC Connectors

General **INFO**

Sales **INFO**

Customer Drawings **SPECIFICATIONS**

9, 12 and 15 Circuit, Matrix

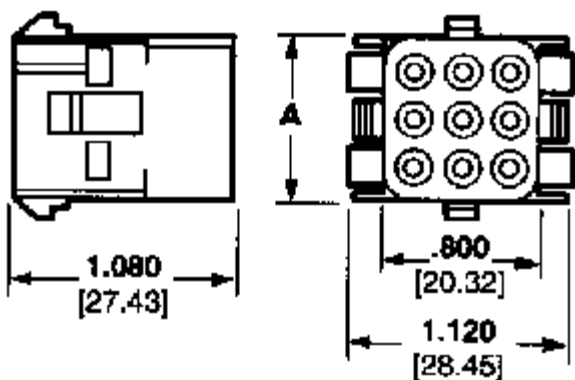

Line art represents typical product only.

[Panel Cutout](#)

Searchable Features:

Product Type	Housing
Connector Line	Universal MATE-N-LOK
Contact Diameter	.084 [2.13] in. [mm]
Centerline	.250 x .250 [6.35 x 6.35] in. [mm]
# of Circuits	12
Contact Layout	Matrix
Mating Type	Cap
Mount	Free or Panel
Packaging Method	One Piece Housing
Housing Material	Nylon
Color	White
Lock Type	Positive Lock

Other Properties:

Dim. A	1.050 [26.67] in. [mm]
Dim. A (Panel Cutout)	1.065 [27.05] in. [mm]
Dim. B (Panel Cutout)	.480 [12.19] in. [mm]
Dim. C (Panel Cutout)	.275 [6.99] in. [mm]
Dim. D (Panel Cutout)	1.030 [26.16] in. [mm]
Dim. E (Panel Cutout)	.350 [8.89] in. [mm]
Housing Flammability Rating	UL 94V-0