


NATV17-PP

Galet de roulement

Yoke type track rollers NATV..-PP-A, single row needle roller bearings with particularly thick-walled outer ring, full complement needle roller set and an inner ring, axial guidance of outer ring is provided by the plastic axial plain washers and contact washers, three-stage sealing by plastic axial plain washer on both sides

Information technique

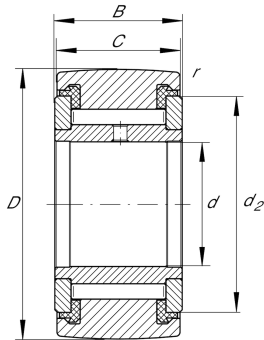

Votre alternative produit actuelle

Joint	PP	Joint frottant des deux côtés
profile bague extérieure	IOP	Profil INA optimisé
dispositif de lubrification	IR	Via la bague intérieure

dimensions principale & données de performance

d	17 mm	Alésage
D	40 mm	Diamètre extérieur
B	21 mm	Largeur, bague intérieure
C _{r w}	14.700 N	Charge dyn. de base, radiale
C _{0r w}	27.000 N	Charge stat. de base, radiale
C _{ur w}	3.550 N	Limite à la fatigue, radiale
n _{D G}	1.400 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	27.000 N	Charge radiale statique admissible
F _{r per}	24.900 N	Charge radial dynamique admissible sur bague extérieure
≈m	0,142 kg	Poids

Dimensions

C	20 mm	Largeur, bague extérieure
d ₂	31,5 mm	Diamètre extérieur rondelle de butée
r _{min}	1 mm	Dimension minimum de chanfrein



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés