

Previously known as: MICROGARD® 2500 Overboots - Model 406

Durable and breathable safety overboots designed with microporous laminate technology.

- **Certified performance:** AlphaTec® 2500 STANDARD Overboots Bound - Model 406 is designed with fabric that satisfies EN 14126 standards and offer ultrasonically welded seams, providing superior personal protection from biological agents - penetration of blood, bodily fluids and blood-borne pathogens
- **Advanced defenses:** In addition to affording chemical resistance, these safety overboots also grant excellent mechanical strength with superb liquid and particulate protection, thanks to their unique, microporous polypropylene laminate fabric
- **Reduced contamination risks:** Composed of low-lint material, these protective overboots do not pose any risk of contamination and are suitable for use in critical areas



Industries

- Life Sciences
- Industrial
- Chemical
- Nuclear
- Law Enforcement


Applications

- Transferring liquids and solids
- Spill or leakage cleanup
- Maintenance
- Unexpected leakages spills or other releases
- Plant disinfection and sanitization
- Emergency Response
- Contaminated Environments


KEY FEATURES & BENEFITS

- **EN-certified protection from biohazards:** Ideal safety footwear
- **Unique material:** For durable, chemical and biological protection
- **Low linting:** Enhanced product protection in critical areas

Material Diagram

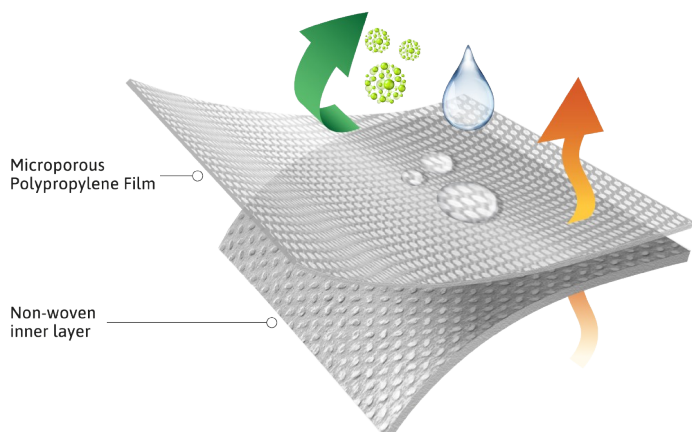

Seam Diagram

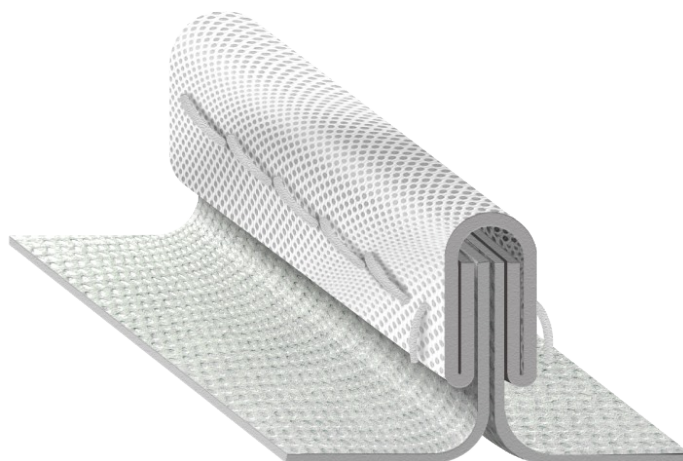

Performance Standards



Product Information

Product Information	
Available Sizes	One Size
Color	White
Country Of Origin	China, Sri Lanka
Packaging Overview	50 pairs every compressed bag
Product Material	Microporous Polypropylene Laminate non-woven
Product Reference	2500 Overboots - Model 406
Standards Overview	CE CATEGORY III (Type PB (6)-B, EN 14126)
Seam Type	Bound
Shelf Life	5 years
Style Number	W25B406

Suit components & accessories

Suit Components and Accessories	
Design Features	Overboots, elastic to top of boot, tie fastening.

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region
Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia
Ansell Limited
T: +61 1800 337 041

Asia Pacific Region
Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

