


SIVACON, base, with side cable entry, T: 600 mm, W: 1200 mm, zinc-plated

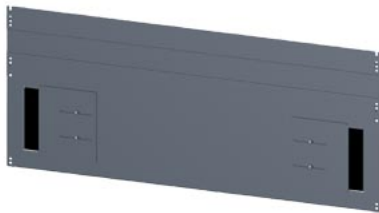

Model	
product brand name	SIVACON
design of the product	With lateral cable entry
design of the surface	zinc plated
design of the product EMC version	No
material	steel
product component	
• ventilation	No

Mechanical Design	
width	1 200 mm
depth	600 mm
net weight	9 400 g

Approvals Certificates

General Product Approval	Test Certificates	other
 EG-Konf.	 UKCA	 EAC

[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------


[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1026-2UB51-2>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1026-2UB51-2>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1026-2UB51-2
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

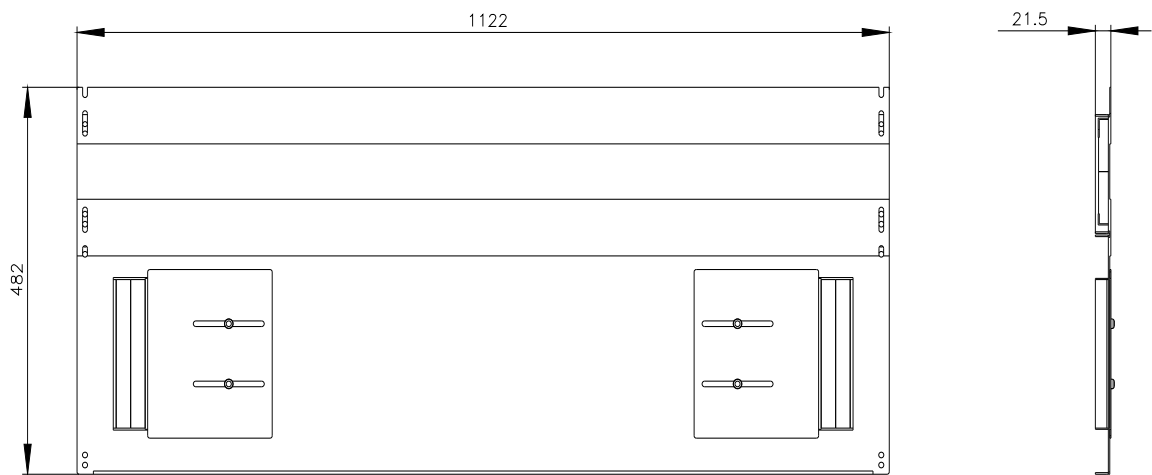

last modified:

6/3/2024 

