

BE-6400M/SET Set of extra thin-walled nut drivers, Metric

Ergonomically developed 3-component handle of polypropylene and thermoplastic elastomer. Permanent colour code on both ends of handle for easy identification of screw nut type. For applications in electronics.

Finish: Blade matt chrome-plated.

Material: Blade of VANADIUM-EXTRA.

In black heavy duty canvas material with individual PVS pocket for each size of nut driver.



Product code	EAN 731415+	pcs			
BE-6400M/6T	3012203	1	6	4 4.5 5 5.5 6 7	300
BE-6400M/9T	3012210	1	9	2.5 3 3.5 4 4.5 5 5.5 6 7	420

1945TLM Nut drivers with T-handle Long type, with magnet


Finish: Shaft nickel and chrome-plated, with plastic T-handle.
Material: Shaft of VANADIUM-EXTRA, polypropylene handle.



Product code	EAN 731415+	mm	L1 mm	L2 mm	D mm		
1945TLM-8	1830601	1	8	350	370	12	150
1945TLM-10	1830618	1	10	350	370	15	175
1945TLM-13	1830625	1	13	350	370	18	200

1945T Nut drivers with T-handle

Finish: Shaft nickel and chrome-plated, with plastic T-handle.
Material: Shaft of VANADIUM-EXTRA, polypropylene handle.

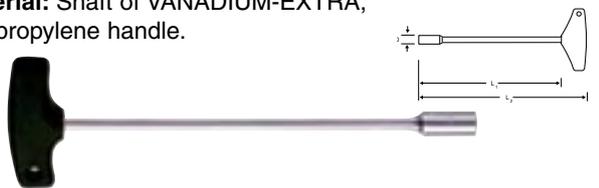

Product code	EAN 731415+	mm	L1 mm	L2 mm	D mm		
1945T-5.5	1830502	1	5.5	230	260	9	90
1945T-6	1830519	1	6	230	260	9	100
1945T-7	1830526	1	7	230	260	11	110
1945T-8	1830533	1	8	230	260	12	130
1945T-9	1830540	1	9	230	260	13	150
1945T-10	1830557	1	10	230	260	15	155
1945T-11	1830564	1	11	230	260	16	170
1945T-12	1830571	1	12	230	260	17	180
1945T-13	1830588	1	13	230	260	18	190

 
111M Combination spanner, offset Metric

DIN 3113/ISO 3318.

Finish: Nickel and chrome-plated, fine-polished.

Material: VANADIUM-EXTRA.

Open-end angle 15°, ring end 15° offset, equal openings at both ends, short type. Dynamic-Drive-Profile™.



Product code	EAN 731415+	mm	L mm	a1xa2 mm	b1xb2 mm	g	
111M-5.5	1828608	1	5.5	105	5.0x3.2	9.5x14	12
111M-6	1828615	1	6	105	5.0x3.2	10.0x14	13
111M-7	1828622	1	7	110	5.6x3.5	11.0x17	18
111M-8	1828639	1	8	110	5.6x3.5	12.0x18	18
111M-9	1828646	1	9	120	6.0x3.8	13.8x20	22
111M-10	1828653	1	10	135	6.6x4.2	15.0x22	30
111M-11	1828660	1	11	135	6.6x4.2	16.5x23	30
111M-12	1828677	1	12	150	7.4x4.7	18.0x26	45
111M-13	1828684	1	13	160	7.4x4.7	19.5x28	45
111M-14	1828691	1	14	168	8.2x5.3	20.6x31	65
111M-15	1828707	1	15	170	8.2x5.3	22.0x32	65
111M-16	1828714	1	16	178	8.8x5.6	23.4x34	80
111M-17	1828721	1	17	190	9.4x6.0	24.8x37	110
111M-18	1828738	1	18	210	10.0x6.3	26.4x39	115
111M-19	1828745	1	19	220	10.0x6.3	27.6x40	120
111M-20	1828752	1	20	232	11.0x7.0	29.0x42	150
111M-21	1828769	1	21	250	11.0x7.0	30.4x44	150
111M-22	1828776	1	22	255	12.0x7.7	31.8x48	200
111M-23	1828783	1	23	255	12.0x7.7	33.4x48	210
111M-24	1828790	1	24	280	13.0x8.4	34.6x50	265
111M-25	1828806	1	25	280	13.0x8.4	36.0x51	270
111M-26	1828813	1	26	280	13.0x8.4	37.5x53	270
111M-27	1828820	1	27	310	14.0x9.2	38.8x57	350
111M-28	1828837	1	28	310	14.0x9.2	40.5x58	365
111M-29	1828844	1	29	310	14.0x9.2	41.0x58	380
111M-30	1828851	1	30	355	15.0x10.0	43.5x62	480
111M-32	1828868	1	32	360	15.0x10.0	46.0x65	500
111M-34	1828875	1	34	380	15.0x10.0	47.0x65	500