

Features


- Premium quality Chloroprene (CR) sheet made to stringent BS 2752 specifications
- High elongation at break for greater flexibility, enhanced tensile strength for added durability
- Guarantees strong, abrasion-resistant properties
- Good weather, oil, and acid resistance (except for aromatics and ketones)
- Good weather, ageing, and oil resistance aswell as handles wear and tear effectively

RS PRO Black BS2752 Grade  
Chloroprene Sheetting

1m x 1.4m x 4mm

+120°C to -30°C

RS Stock No.: 0205562

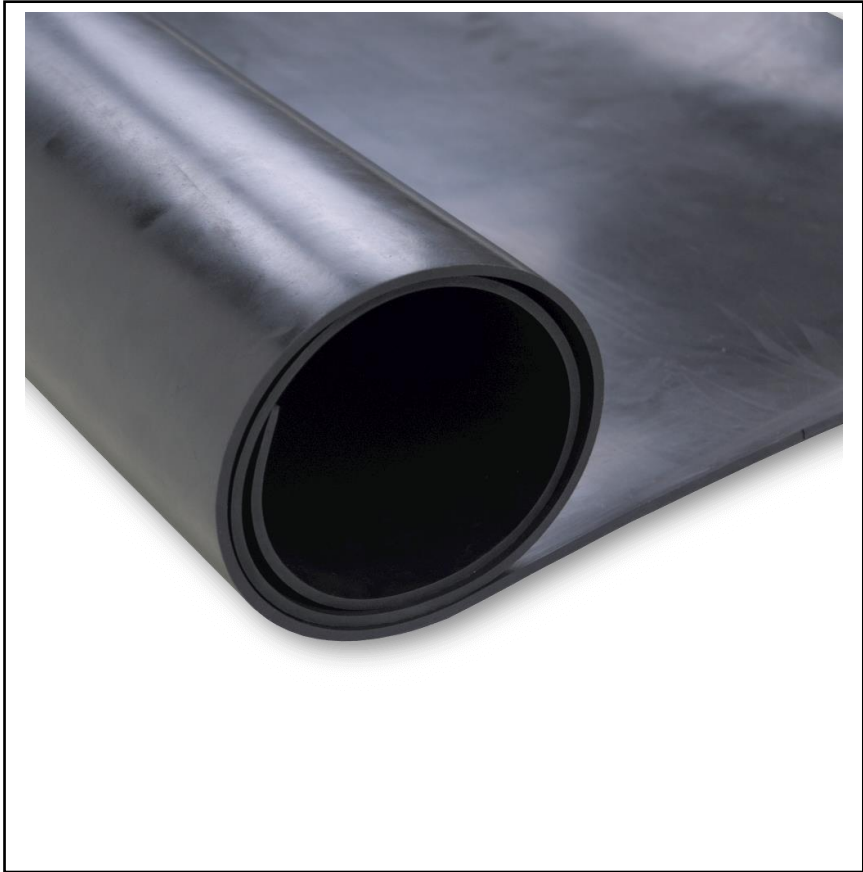

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

*The RS PRO Chloroprene sheet is suitable for a wide range of industrial applications and environments including gaskets, seals, hoses, tubing, liners, protective sleeves.*

General Specifications

Colour	Black
Material	Chloroprene
Adhesive Backing	No

Mechanical Specifications

Length	1m
Width	1.4m
Thickness	4mm
Elongation	450%
Tensile Strength	9 MPa
Hardness	60 ShA

Operation Environment Specifications

Maximum Operating Temperature	120°C
Minimum Operating Temperature	-30°C



Similar Products

Stock No	Length	Thickness	Min Operating Temperature	Max Operating Temperature
0205559	1m	1mm	-30°C	120°C
0205560	1m	1.5mm	-30°C	120°C
0205562	1m	3mm	-30°C	120°C