

Contact insert - SACC-CI-M12FS-5CON - 1528536

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sensor/actuator flush-type socket, 5-pos., M12 contact carrier, A-coded, with straight solder connection



Key commercial data

Packing unit	100 pc
Minimum order quantity	100 pc
GTIN	 4 046356 023443
Weight per Piece (excluding packing)	1.35 g
Custom tariff number	85366990
Country of origin	Poland

Technical data

Ambient conditions

Degree of protection	IP67
----------------------	------

General

Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	5
Contact resistance	≤ 0.003 Ω
Coding	A - standard
Status display	No
Pollution degree	3

Material

Contact material	CuZn
Contact surface material	Au
Sealing material	FKM

Contact insert - SACC-CI-M12FS-5CON - 1528536

Classifications

eCl@ss

eCl@ss 4.0	27140815
eCl@ss 4.1	27140815
eCl@ss 5.0	27143423
eCl@ss 5.1	27143423
eCl@ss 6.0	27143423
eCl@ss 7.0	27449001

ETIM

ETIM 2.0	EC001297
ETIM 3.0	EC002061
ETIM 4.0	EC002061
ETIM 5.0	EC002061

UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31251501

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / cULus Recognized

Ex Approvals

Approvals submitted

Approval details

UL Recognized	
Nominal current IN	4 A
Nominal voltage UN	120 V

Contact insert - SACC-CI-M12FS-5CON - 1528536


Approvals

cUL Recognized	
Nominal current I _N	4 A
Nominal voltage U _N	120 V


cULus Recognized	
------------------	--

Drawings

Drilling diagram

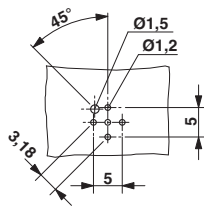


Dimensioned drawing

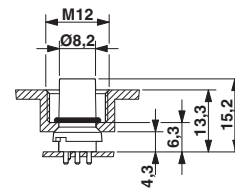


Installation diagram

Schematic diagram

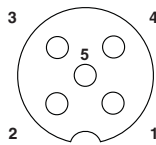

Dimensioned drawing

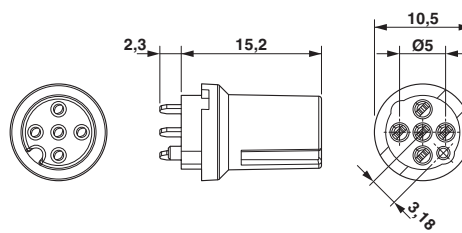

Pin assignment M12 socket, 5-pos., A-coded, socket side view