

Stainless Steel Printing System

- M-BOSS Lite Printer

- M-BOSS Lite Markers

M-BOSS Lite is the ideal stainless steel marker plate embossing printer for low to medium volumes.

Installation is quick and it is very easy to operate. Due to it being small in size, quiet in operation, and able to run off a normal electrical supply, it is very easy to locate within your business.

All sizes will be printed in under a minute.

Features and Benefits

- Marine grade stainless steel marker plate embossing printer for low to medium volumes
- Used to identify pipes and cables
- Used in offshore platforms, floating production storage offloading (FPSO), refineries, rail infrastructure, utilities, food, and solar farms
- Small enough to install in most premises
- Uses a standard electrical supply and only weighs 35kg
- MBML10X45 printed with 8 characters in under 10 seconds
- MBML20X90 printed with 69 characters in less than a minute
- Use 4.6mm wide cable ties and hand tool to securely fix marker plate to cable
- Rivets can be applied to MBML20X90 and MBML20X45 if required
- Comes with 42-piece 4mm character set
- Letters: A B C D E F G H I J K L M
N O P Q R S T U V W X Y Z
- Numbers: 0 1 2 3 4 5 6 7 8 9
- Symbols: & - / . , ' ,



One Step to the Web!



Space-saving and easy to use: M-BOSS Lite stainless steel embossing system.

Patent Pending

Print Method	Embossed
Power Supply	230 Volt 50/60 Hz
Cycle Time	Just under 1 second per character
Printer Interfaces	USB 2.0
System Requirements	Microsoft Windows operating system
L x H x W	650 mm x 260 mm x 500 mm
Weight	35 kg
Specifications	CE

RoHS ✓

TYPE	Width (W)	Length (L)	Pack Cont.	Article-No.
M-BOSS Lite	500.0	650.0	1	544-00000


All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.

MATERIAL	Stainless Steel (SS316)
Operating Temperature	-80 °C to +538 °C

HF ✓

LFH ✓

RoHS ✓

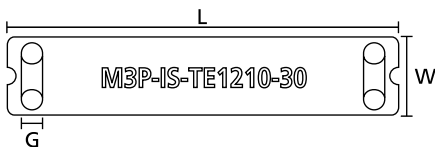

Identification for hazardous environments: M-BOSS Lite stainless steel markers.

TYPE	Strap Width max. (G)	Number of lines	Characters per line	Number of characters	Width (W)	Length (L)	Pack Cont.	Article-No.
MBML10X45	4.6	1	8	8	10.0	45.0	1,000	544-80101
MBML10X90	4.6	1	23	23	10.0	90.0	500	544-80102
MBML20X45	4.6	3	8	24	20.0	45.0	1,000	544-80201
MBML20X90	4.6	3	23	69	20.0	90.0	500	544-80202

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval. For product specific approvals please refer to the Appendix.