


pressure gauge MA-50-36-R1/4-PSI-E-RG

Part number: 526788

FESTO

With display unit in psi, adjustable red/green range.

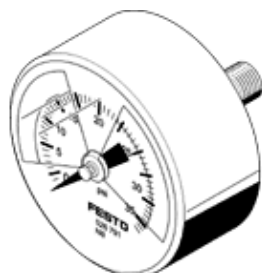

Data sheet

Feature	Value
Indicating range [psi]	0 ... 36 psi
Conforms to standard	EN 837-1
Nominal size of pressure gauge	50
Design structure	Bourdon-tube pressure gauge
Mounting type	Line installation
Operating medium	Inert gases Neutral fluids
Operating pressure	0 ... 36 Psi
Alternating load factor	0.66
Measurement accuracy class	2,5
Protection class	IP43
Medium temperature	-20 ... 60 °C
Ambient temperature	-20 ... 60 °C
Materials note	Conforms to RoHS
Position of connection	Rear side central
Pneumatic connection	R1/4
Materials in contact with media	Brass
Material of threaded plug	Brass
Material housing	ABS
Material screen	PMMA
Housing colour	Black
Product weight	75 g
Note on operating and pilot medium	No acetylene No oxygen