

CONTI[®]V GARDEN


Heavy-duty V-belt for good slip control and noiseless clutch engagement.
Specially developed for machines used in garden and park upkeep



Properties:

- Temperature-resistant from -30 °C to +80 °C
- Resistant to high shock loads
- Suitable for counterflexing/tension pulleys
- Tropic-proof
- Dust-proof

Belt structure:

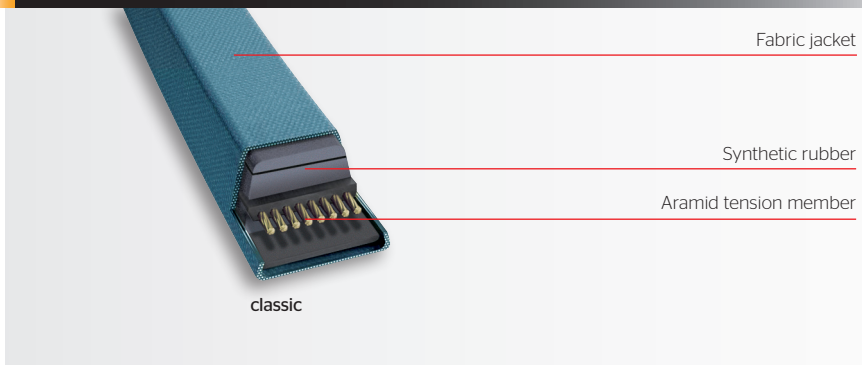

classic

Profile	Length range RMA (1/10 inch)
3L	3L 170 - 3L 750
4L	4L 180 - 4L 990
5L	5L 290 - 5L 990

The content of this publication is not legally binding and is provided as information only. The trademarks displayed in this publication are the property of Continental AG and/or its affiliates. Copyright © 2015 ContiTech AG. All rights reserved. For complete information go to: www.contitech.de/disclosure