


Product Data Sheet

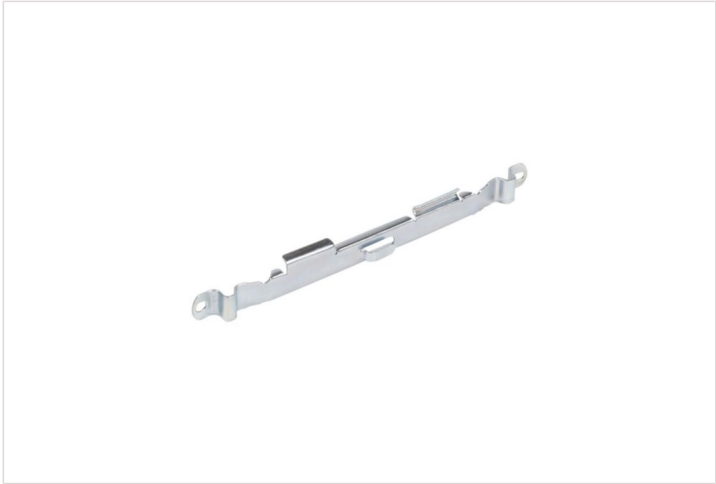

CABLOFIL LEGRAND

Cablofil Electro Zinc Steel Wire Cable Tray Tool Mounted Coupler

REF. CM558241 | EAN. 3599075582414

> [Link to e-catalog product sheet](#)

Description

Supplied with one fixing tool in each pack of 50 couplers

Technical characteristics

Model	Longitudinal joint
Hinged joint horizontal	Yes
Hinged joint vertical	No
Type of connection	Snapable
Suitable for wire mesh tray	Yes
Suitable for cable ladder	No
Suitable for cable tray	No
Suitable for cable support system width	50-600 mm
Suitable for cable support system height	50-50 mm
Length	250 mm

Suitable for circuit integrity	No
Material	Steel
Stainless steel, pickled	No
Material quality	Other
Surface protection	Galvanic/electrolytic zinc plated
Operating / setting temperature	-20-120 °C
Colour	Zinc
Storage temperature	-20-120 °C
Halogen free	Yes

Documents

Technical documentation

-  LE07941AA.pdf | PDF (0.35Mo)
-  FT0026-01_CABLO.pdf | PDF (1.19Mo)

Catalogue pages

-  cablofil-cable-tray-2023-032.pdf | PDF (0.72Mo)