


Terminals

**Part Number: 7910240000**

WTR 4 SI

Fuse terminal

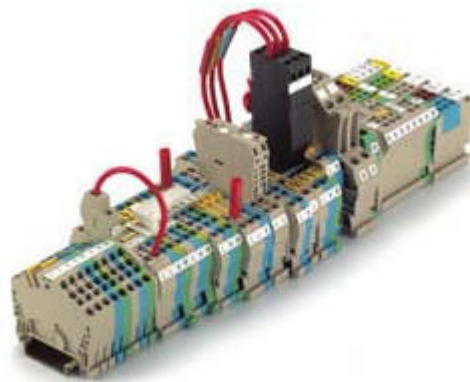

Representative Photo

#### Selected Features

Installation advice	TS 35
Type of connection	Screw connection
Insulation material	Wemid
Rated voltage	400 V
Rated current	24 A
Rated cross-section	4 mm <sup>2</sup>
Version	Fuse terminal
Colour of insulating material	dark beige
Rated impuls voltage	6 kV

#### Additional Technical Data

EAN	4008190576820
Width	6 mm
Length	60 mm
No. of identical terminals	1
Voltage UL	600 V
Voltage CSA	600 V
Current CSA	24 A
min. conductor	0.13 mm <sup>2</sup>
max. conductor	6.0 mm <sup>2</sup>
Height with TS	82 mm
Degree of soiling	3
Strom UL	24 A
Type of Cross-connection 1	ZQV
Type of Cross-connection 2	QB
Stripping length	13 mm
Blade size / AF size	3.5 x 0.6 mm
Solid, min.	0.5 mm <sup>2</sup>

<b>Solid, max.</b>	4 mm <sup>2</sup>
<b>Stranded, min.</b>	1.5 mm <sup>2</sup>
	4 mm <sup>2</sup>
<b>Flexible, min.</b>	0.5 mm <sup>2</sup>
<b>Flexible, max.</b>	4 mm <sup>2</sup>

---

**Product Liability** The above information describes our products. It does not constitute guaranteed properties and is not intended to affirm the suitability of a product for a particular application. Regrettably, omissions and exceptions cannot be completely ruled out. Technical data are always specified by their average values. Exact data and the tolerances which apply to our processes can be requested from: