



Brand of NTN corporation

Technical data

UCFL205

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC205G2, FL205

VISUAL (S)

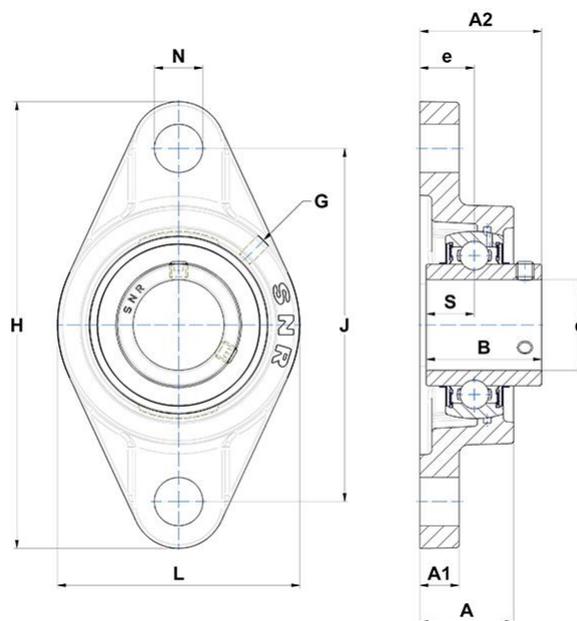

PRODUCT DEFINITION

Brand	SNR
A - Housing height	27 mm
A1 - Housing foot height / flange height	13 mm
A2 - Total height from mounting surface	35,7 mm
B - Width of Inner Ring	34 mm
d - Shaft diameter	25 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	16 mm
G - Grease fitting	M6x1
H - Housing length, width or diameter	130 mm
J - Mounting holes distance	99 mm
L - Housing width / diameter	68 mm
N - Mounting hole dimension	16 mm
S - Distance front side/bearing centre	14,3 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	14000000 mN
C0 - Static load rating	7880000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,62 kg
Recommended tightening torque for set screw	5.5 N-m

