

F40W T12 BL368 24

Item No: 0001638

SYLVANIA


SpeciaLITE®



Blacklight BL368 Linear T12

Technical Assets

Dimensions (mm)

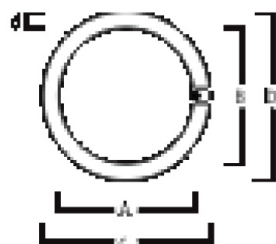

Photometrics

F40W T12 BL368 24

Item No: 0001638

SYLVANIA

General data

Product name	F40W T12 BL368 24
Technology	Fluorescent
Lamp shape	Tubular shape
Cap/Base	G13
Lamp finish	Frosted/Coated
Fixture rating	Enclosed
General application	SPG
Operating temperature range (°C)	-20°C...+40°C
ETIM Class	EC002962
E-number FI	4940437

Optical data

Ambient temperature for maximum luminous flux (°C)	25
Light colour	BL368 Blacklight
Adjustable chromaticity	N

Electrical data

Power consumption (W)	40
Wattage (W)	40.00
Primary Supply/Product voltage - min (V)	230
Primary Supply/Product voltage - max (V)	240
Control gear required	Yes
Dimmable	No
Dimming method	N/A

Lifetime data

Average life (Nominal) (h)	10000
----------------------------	-------

Physical data

Nominal Product Length (mm)	600.0
Nominal Product Diameter (mm)	38
Max. Length base to base (mm) - A	589.8
Length base to pin Min-Max (mm) - B	594.5-596.9
Max. Lamp Length (mm) - C/L	604.0
Max. Lamp Diameter (mm) - D	40.5
Weight (kg)	0.136

Packaging

Product EAN number	5410288016382
Packaging single length / height (cm)	60.5
Packaging single width (cm)	4.0
Packaging single depth (cm)	4.0
DUN14 (inner)	15410288016389
Units per outer package	25
Packaging outer length / height (cm)	63.0
Packaging outer width (cm)	21.6
Packaging outer depth (cm)	21.6

Safety data

Lamp mercury content (mg)	9.00
Optimal operating condition (°C)	-20-40
Breakage cleaning instructions	Applicable
Recommendation for disposal at end of life	Applicable
Special purpose lamp	Yes
Intended purpose	Flykilling - Insect attraction
Suitable for household illumination	No
Safety message	Not suitable for household