

### Labels for control panel identification, thermal transfer

**Helatag 880 (Yellow matt), removable**

**Helatag 1211 (Yellow) for rough surfaces**

The specially formulated adhesive labels give the highest quality print clarity when printed on thermal transfer printers. The range of materials and ribbons have been developed to suit the needs of most users. Designing and printing labels is simple and users can quickly print out professional labels in a matter of moments when using TagPrint Pro labelling software.


Due to the structure of the vinyl label they are suitable for rougher surfaces.

#### Features and Benefits

- Suited to labelling electrical panels
- Excellent print performance using TT822OUT ribbon
- Print with TT4000+, TT430 for best results
- Easy label design with TagPrint Pro



Switchgear application.

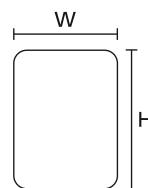

<b>MATERIAL</b>	Type 880, Vinyl, yellow matt (MTYE), removable
<b>Operating Temperature</b>	-40 °C to +80 °C
<b>Curing Temperature</b>	from +10 °C
<b>Adhesive</b>	Acrylic
<b>Thickness of Foil (µm)</b>	80 µm
<b>Chem. Material Properties</b>	Good resistance to water, oil and most solvents.
<b>Recommended Ribbon Type</b>	TT822OUT



<b>MATERIAL</b>	Type 1211, Vinyl (PVC), yellow gloss (GSYE)
<b>Operating Temperature</b>	-20 °C to +80 °C
<b>Curing Temperature</b>	from +5 °C
<b>Adhesive</b>	Acrylic
<b>Thickness of Foil (µm)</b>	83 µm
<b>Chem. Material Properties</b>	Resistant to water, alcohol, most oils, greases, fuel, aliphatic solvents, weak acids, salts and alkalis.
<b>Recommended Ribbon Type</b>	TT822OUT



TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG15-09TE-880-YE	15.0	9.0	89.0	5	10,000 pcs.	Yellow matt (MTYE)	596-12174
TAG16-06TE-880-YE	16.5	6.0	101.6	5	20,000 pcs.	Yellow matt (MTYE)	596-12172
TAG19-11TE-880-YE	19.0	11.0	89.0	4	10,000 pcs.	Yellow matt (MTYE)	596-12175
TAG20-08TE-880-YE	20.0	8.0	101.6	4	10,000 pcs.	Yellow matt (MTYE)	596-12173
TAG38-11TE-880-YE	38.0	11.0	85.1	2	5,000 pcs.	Yellow matt (MTYE)	596-12176
TAG56-22TE-880-YE	56.0	22.0	62.0	1	2,000 pcs.	Yellow matt (MTYE)	596-12177

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

TYPE	Width (W)	Height (H)	Width of Liner (WL)	Labels per Row	Pack Cont.	Colour	Article-No.
TAG15-09TE-1211-YE	15.0	9.0	89.0	5	10,000 pcs.	Yellow gloss (GSYE)	596-21211
TAG16-06TE-1211-YE	16.5	6.0	101.6	5	20,000 pcs.	Yellow gloss (GSYE)	596-01211
TAG20-08TE-1211-YE	20.0	8.0	101.6	4	10,000 pcs.	Yellow gloss (GSYE)	596-11211
TAG38-11TE-1211-YE	38.0	11.0	85.1	2	5,000 pcs.	Yellow gloss (GSYE)	596-41211
TAG56-22TE-1211-YE	56.0	22.0	62.0	1	2,000 pcs.	Yellow gloss (GSYE)	596-51211

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.