


## Category 5e & Category 6 Faceplates

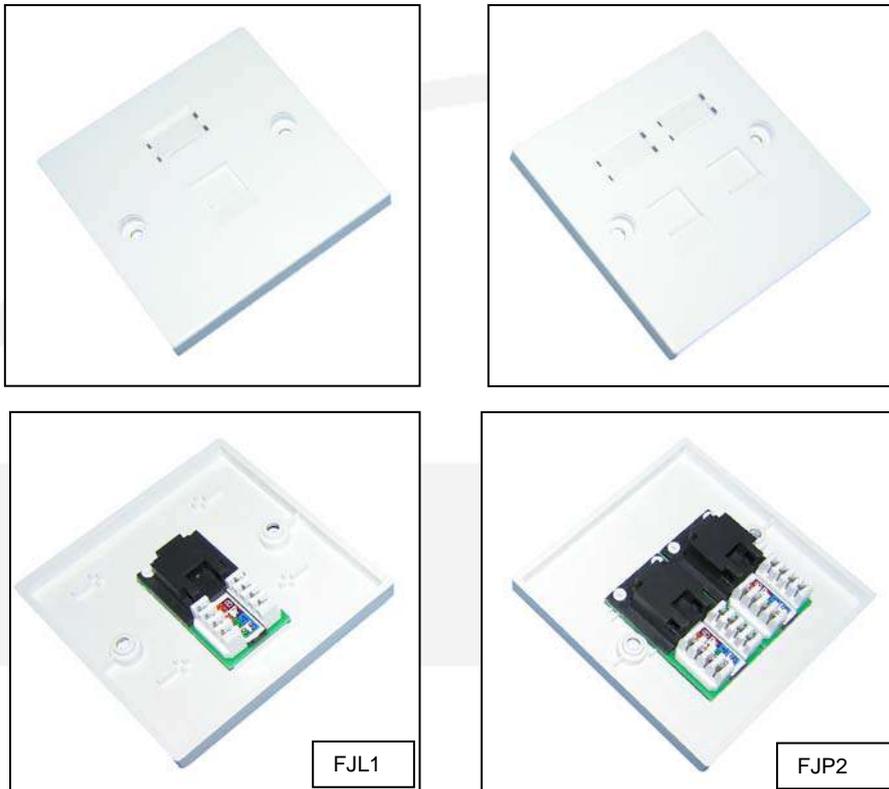

### Category 5e & 6 Faceplates (FJL1, FJP2, SJL1 & SJP2)

Cat5e/Cat 6 component level socket mounted in a single or double port faceplate and requiring a standard back box for installation.

For additional security and improved appearance the sockets are supplied with screw caps to discourage unauthorised tampering. The shuttered front aperture protects against ingress of dust.

A 'slip-in' labelling field is located above each outlet for port identification.


#### Features

- Performs to Category 5e/Category 6 specifications
- Very compact design - both versions fit standard UK 86x86mm back box
- Industry standard LSA+ type terminations, colour coded to T568B
- Labelling facility
- Supplied with cable ties, screws, screw caps

#### Specifications

- TUK codes: Cat5e single FJL1, double FJP2, Cat6 single SJL1, double SJP2
- Dimensions: 86x86x19mm
- Colour: Bright white
- Weight: Single outlet 42g, double outlet 51g
- Material: faceplate – ABS, PCB – FR4



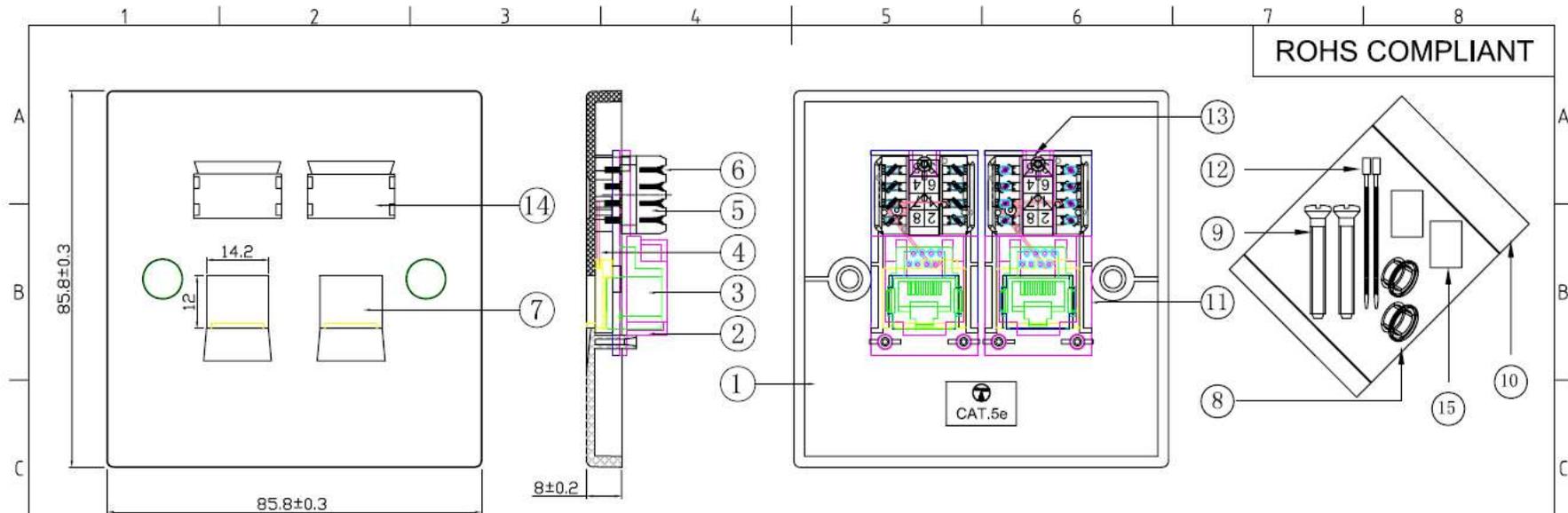


⑤	Label 2	PAPER	17X12X0.25	2	ZPZ000003	
④	COVER	PC	Transparent	2	AHM1008XXXXX-05	
⑬	Label 1	PAPER	18.8x6.8	2	KLXXXX756	
⑫	CABLE TIE	Nylon	2.5x80mm	2	ZP101XXXX	
⑪	PCB	FR-4	1.6mm Thickness	2	ZPTUKPTX-C61	
⑩	Plastic Bag	PE	Transparent (4x12CM)	1	KPXX232	
⑨	SCREW	IRON	3.5X26	2	SCB3.5X26XBB22X	
⑧	SCREW COVER	ABS	WHITE(KI)	2	AH8104X3XXXX	
⑦	SHUTTER	ABS	WHITE(KI)	2	AHPLAT8XXXXX-02	
⑥	IDC HOUSING	PC	4P WITH PROTECTION COATING	4	AHIDCX4BXXXX	
⑤	IDC CONDUCTOR	PHOSPHOR COPPER	NICKEL PLATED	16	NIDBN-1B	
④	Spring	stainless steel		2	ZTAC601XX	
③	064 JACK	PBT	8P8C PD/NI 20U"+0.8U" Gold	2	JP064MX88XXXXXX-3	
②	FRONT COVER	ABS	BLACK (42)	2	AHPLAT8XXXXX-01	
①	PLATE HOUSING	ABS	85.8x85.8x8.0mm WHITE(KI)	1	AHPLA28XXXXX-5e	
F	No.	NAME	MATERIAL	SPECIFICATION	QTY	REMARK

APPD.		P/N	FJP2
CHKD.		FILE	
DR.		TITLE	Cat5e double port faceplate

		<b>TUK LTD</b>			SCALE	/	SIZE	A4
REV.	Revision note				Date	ENG	APPROVAL	UNIT

TUK Ltd, Unit 4, Wimbledon Stadium Business Centre, Riverside Road, London, SW17 0BA

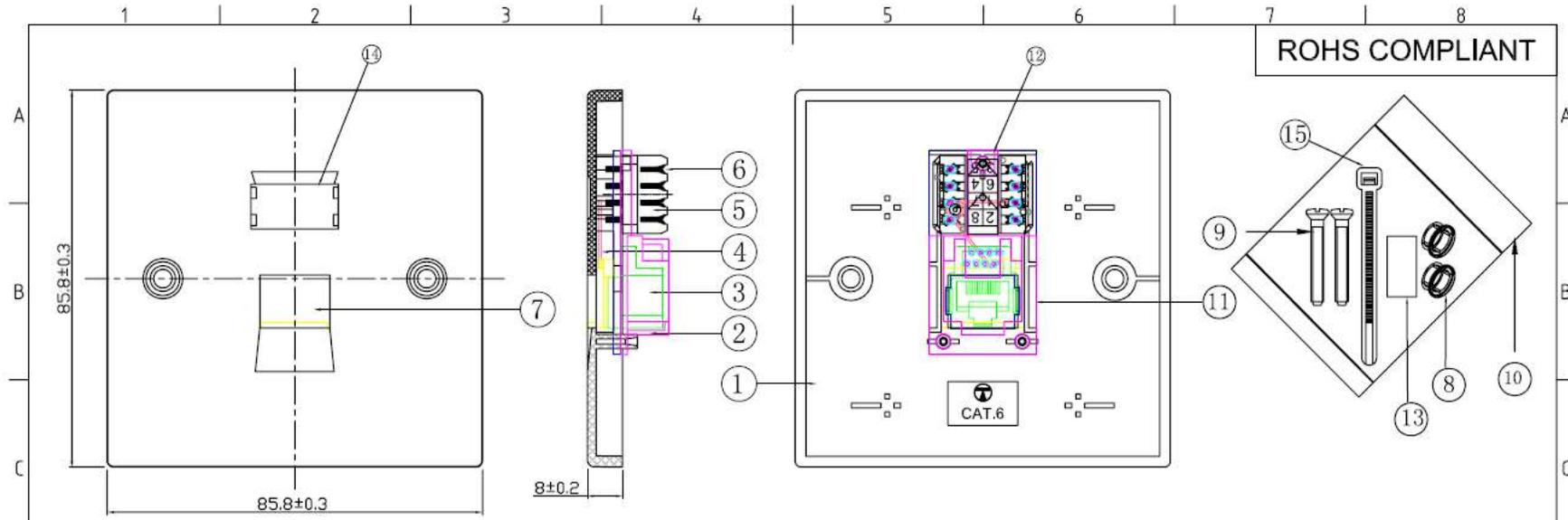


⑮	CABLE TIE	Nylon	2.5x80mm	1	ZP101XXXX
⑭	Transparent COVER	PC	Transparent	1	AHM1008XXXXX-05
⑬	Label 2	PAPER	17X12X0.25	1	ZPZ000003
⑫	Label 1	PAPER	18.8x6.8	1	KLXXXX756
⑪	PCB	FR-4	1.6mm Thickness	1	ZPTUKPTX-C61
⑩	Plastic Bag	PE	Transparent (4x12CM)	1	KPXX232
⑨	SCREW	IRON	3.5X26	2	SCB3.5X26XBB22X
⑧	SCREW COVER	ABS	WHITE(KI)	2	AH8104X3XXXX
⑦	SHUTTER	ABS	WHITE(KI)	1	AHPLAT8XXXXX-02
⑥	IDC HOUSING	PC	4P WITH PROTECTION COATING	2	AHIDCX4BXXXX
⑤	IDC CONDUCTOR	PHOSPHOR COPPER	NICKEL PLATED	8	NIDBN-1B
④	Spring	stainless steel	—	1	ZTAC601XX
③	064 JACK	PBT	8P8C PD/NI 20U"+0.8U" Gold	1	JP064MX88XXXXXX-3
②	FRONT COVER	ABS	White	1	AHPLAT8XXXXX-01
①	PLATE HOUSING	ABS	85.8x85.8x8.0mm WHITE(KI)	1	AHPLAT8XXXXX
No.	NAME	MATERIAL	SPECIFICATION	QTY	REMARK

APPD.		P/N	SJL1	
CHKD.		FILE		
DR.		TITLE	Cat6 single port faceplate	

A1					<b>TUK LTD</b>	SCALE	/	SIZE	A4
REV.	1	Revision note	2	Date		3	UNIT	MM	REV
	4	ENG	5	APPROVAL	6				

TUK Ltd, Unit 4, Wimbledon Stadium Business Centre, Riverside Road, London, SW17 0BA

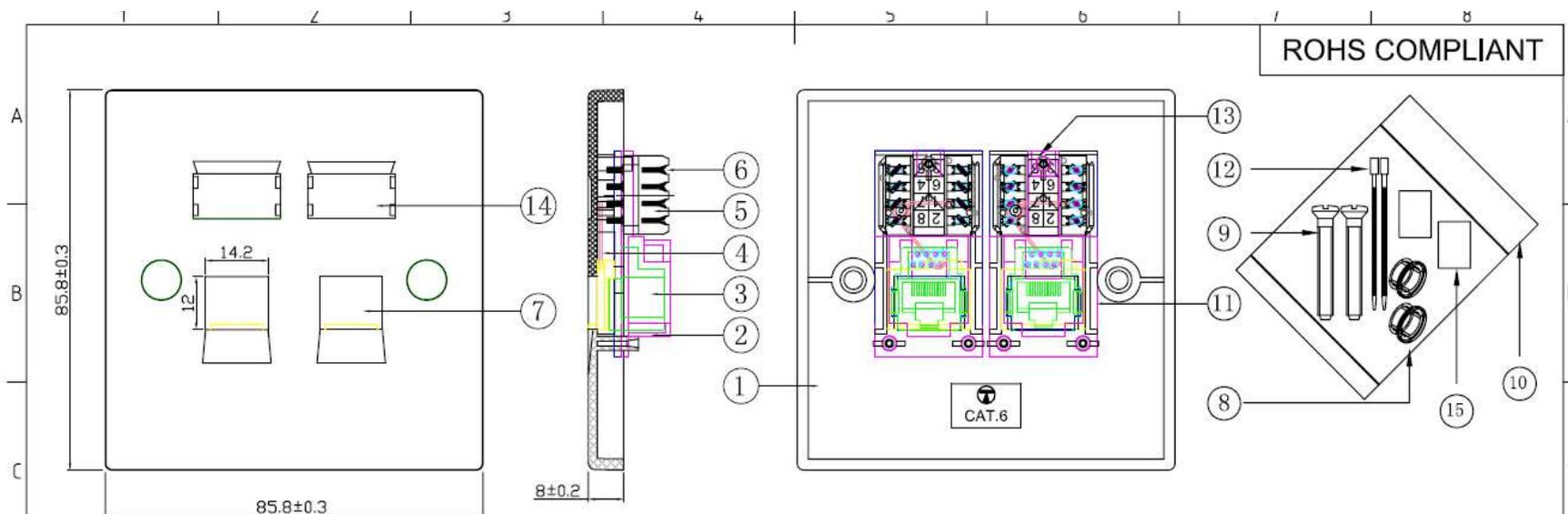

15	Label 2	PAPER	17X12X0.25		ZPZ000003	
14	COVER	PC	Transparent		AHM1008XXXXX-05	
13	Label 1	PAPER	18.8x6.8	2	KLXXXX756	
12	CABLE TIE	Nylon	2.5x80mm	2	ZP101XXXX	
11	PCB	FR-4	1.6mm Thickness	2	ZPTUKPTX-C61	
10	Plastic Bag	PE	Transparent (4x12CM)	1	KPXX232	
9	SCREW	IRON	3.5X26	2	SCB3.5X26XBB22X	
8	SCREW COVER	ABS	WHITE(KI)	2	AH8104X3XXXX	
7	SHUTTER	ABS	WHITE(KI)	2	AHPLAT8XXXXX-02	
6	IDC HOUSING	PC	4P WITH PROTECTION COATING	4	AHIDCX4BXXXX	
5	IDC CONDUCTOR	PHOSPHOR COPPER	NICKEL PLATED	16	NIDBN-1B	
4	Spring	stainless steel		2	ZTAC601XX	
3	064 JACK	PBT	8P8C PD/NI 20U"+0.8U" Gold	2	JP064MX88XXXXXX-3	
2	FRONT COVER	ABS	WHITE(KI)	2	AHPLAT8XXXXX-01	
1	PLATE HOUSING	ABS	85.8x85.8x8.0mm WHITE(KI)	1	AHPLA28XXXXX	
F	No.	NAME	MATERIAL	SPECIFICATION	QTY	REMARK

APPD.		P/N	SJP2
CHKD.		FILE	
DR.		TITLE	Cat6 double port faceplate

		TUK LTD		SCALE	/	SIZE	A4	
REV.	Revision note			Date	ENG	APPROVAL	UNIT	MM