



order number : 736

Receptacle


internal fixing, one cable entry at the top, two blind cable entries (can be cut out) at the bottom, enclosure can be turned 180°

with high heat resistant contact carriers and nickel plated contacts

32A7P 6H400V wallmounted receptacle

IP44

with high heat resistant contact carriers and nickel plated contacts

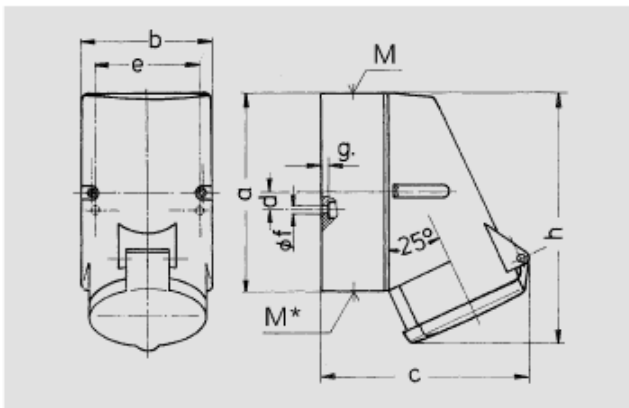

Zeichnung	Amp.	16	32
1 MB 257	Pole	7	7
Maße in mm	a	128	128
	b	84	84
	c	119	133
	d	11	11
	e	68	68
	f	5,3	5,3
	g	4	4
	h	145	160
	M	32	32
	M*	für 2x32 (blind)	für 2x32 (blind)
		zum Ausschneiden	zum Ausschneiden
Leitung bis mm Ø		25	25
Klemmen für Leiterquerschnitt von bis mm ²		1,5—4	2,5—10

Article-group : **1041**

voltages : 400V

rated current : 32A

pole : 7 pole

IP protection types : IP44

position of ground contact : 6h

packing unit : 0010







pilot contact (63A-125A) : without pilot-contact

contact carriers : reliable contact frame

contact technique : screw contact

weight : 463 g

PART NUMBERS

V	110V	230V	400V	500V	>50-500V	
Hz	50,60	50,60	50,60	50,60	100-300	300-500
colour						
amp.						
16 A	7	733	734	1035		
32 A	7	735	736	1040		