




# ANT-WP433M4-Y

## 433MHz Waterproof Whip Antenna

Electrical Specifications	
Frequency Range	433MHz
Nominal Impedance	50 $\Omega$
Maximum Input Power	50W
Polarization	Vertical
Radiation Pattern	Omni
Gain	1.8dBi
VSWR	$\leq 1.5$
Connector	M4 female

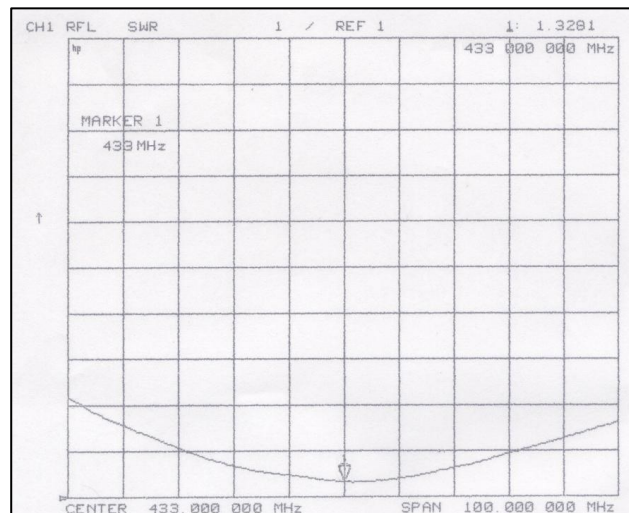

Mechanical Specifications	
Material	Rugged Antenna
Antenna dimensions	90mm x 12mm
Antenna weight	11g
Ambient Temperature	-40°C to 60°C

<b>Order Code</b>	ANT-WP433M4-Y
-------------------	---------------