


Datasheet



Plumber's Vice

High quality vice made from drop forged steel and surface-hardened for **long life**. The **double acme thread screw** allows faster adjustment of the jaw opening and is enclosed to keep dirt and debris out of the mechanism. K2 vices are available with jaw widths from 100 mm to 180 mm.

Solid Body: Drop-forged from high quality steel. Drop forged. Induction hardened. Solid with the body. Ideal for straightening or similar jobs requiring strong and flat surface. **Unbreakable.**

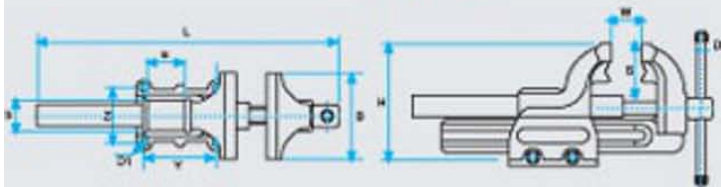

Jaws: Solid with drop forged body. Ground and CNC- machined for perfect grip. Induction hardened for endurance and added strength. Pipe jaws **forged integral with the body**, standard in all sizes. Ideal for plumbers and other professions where pipe and tube work is also part of the day.

	RS code	7719271	7719275
Size		120	140
Jaw Width	B	120	140
Jaw Opening	W	150	200
Jaw Depth	S	70	87
Vice height	H	170	202
Anvil Size	axb	50x40	58x55
Screwhandle	D2	13	15
Hole Diameter	D1	11,5	11,5
Total Length	L	376	465
Weight ~	kg	9	16
Hole Distance	YxZ	97x76	119x95
Clamps pipes from / to		ø16-ø58	ø18-ø80