



Identification ties and plates for marking cable bundles

IT Ties

One of the major benefits is the ability to both secure and identify cable bundles at different times.

Features and benefits

- Identification ties made of Polyamide 6.6
- For simple identification and securing of cable bundles in one step
- Printable labels are available for a professional finish
- Manual or temporary marking is possible with an indelible pen (T825-BK / T82R-RD)




One operation with two user benefits.




Identification ties and tags.

MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-40 °C to +85 °C
Flammability	UL 94 V2

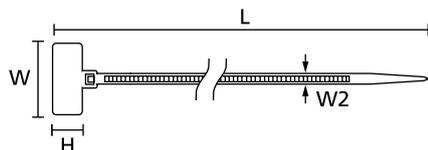

IT18FL

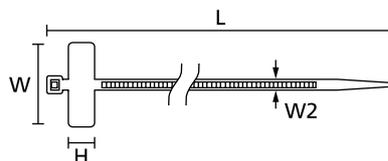

IT18R



= Minimum Loop Tensile Strength for Cable Ties (newton)



TYPE	Bundle Ø min.	Bundle Ø max.	Width (W)	Height (H)	Length (L)	Width (W2)	N	Recommended Labels	Pack Cont.	Colour	Tools	Article-No.
IT18FL	1.5	19.0	20.5	9.0	110.0	2.5	80	TAG18-07TD1	100 pcs.	Natural (NA)	2;4-6	111-81919
IT18R	6.0	22.0	25.0	8.0	100.0	2.5	80	TAG23-06TD1	100 pcs.	Natural (NA)	2;4-6	111-81821

Recommended Tools: 2=MK20, 4=MK3PNSP2, 5=EVO7i, 6=MK7P. For more information on toolings please refer to the Application Tooling chapter on page 346.

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available. More colours on request.




Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.




Identification ties and plates for marking cable bundles


IT Ties

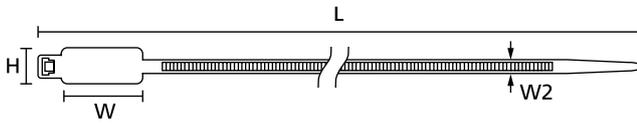


IT50R

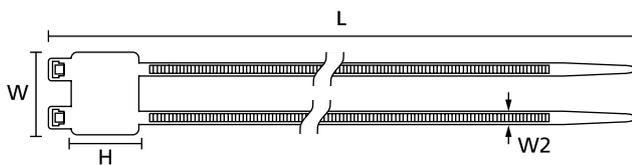

IT50RD

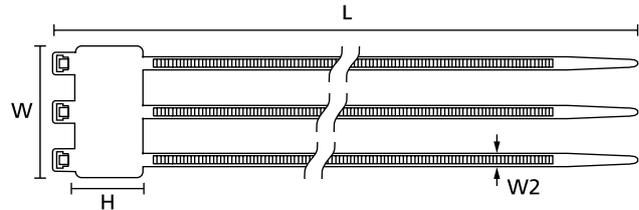

IT50RT

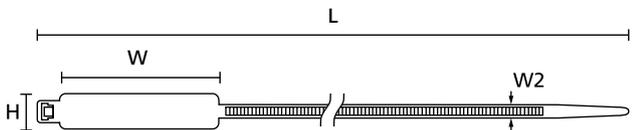

IT50L

= Minimum Loop Tensile Strength for Cable Ties (newton)



TYPE	Bundle Ø min.	Bundle Ø max.	Width (W)	Height (H)	Length (L)	Width (W2)		Colour	Pack Cont.	Tools	Article-No.
IT18R	6.0	22.0	25.0	8.0	100.0	2.5	80	Black (BK)	1000 pcs.	2;4-6	111-81860
IT50R	9.5	44.5	28.0	12.9	203.2	4.6	225	Natural (NA)	100 pcs.	2-7;9	111-85019
IT50RD	10.0	44.0	29.0	26.3	203.2	4.7	225	Natural (NA)	50 pcs.	2-7;9	111-85219
IT50RT	10.0	44.0	46.0	26.3	203.2	4.7	225	Natural (NA)	50 pcs.	2-7;9	111-85119
IT50L	19.0	100.0	56.0	12.8	390.0	4.7	225	Natural (NA)	100 pcs.	2-7;9	111-85319

Recommended Tools: 2=MK20, 3=MK21, 4=MK3PNSP2, 5=EVO7i, 6=MK7P, 7=EVO9i, 9=EVO9iHT. For more information on toolings please refer to the Application Tooling chapter on page 346.

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available. More colours on request.



Please note! Not all products listed on this page may have this approval. Please check our website for latest approvals.