


Product data sheet

Specifications

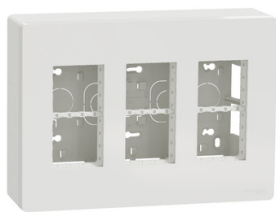

Repacked Workstation, New Unica, Surface, 3 x 4 modules vertical, white

NU123418W



This repacked option saves 3.459 over the standard condition

Main

Range	New Unica
Product or component type	Workstation
Number of modules	3 x 4 modules
Mounting position	Vertical
fixing mode	Screws

Complementary

Provided equipment	Cover frame Fixing frame
Device mounting	Surface
Cable entry	5 removable plates 2 bottom cable entries 30 mm for diameter 2 bottom cable entries 20 mm for diameter 2 bottom cable entries 25 mm for diameter
Material	ABS (acrylonitrile butadiene-styrene): box ABS (acrylonitrile butadiene-styrene): separator ABS (acrylonitrile butadiene-styrene): cover frame
Depth	60 mm
Width	230 mm
Height	165 mm
Product weight	0.508 kg
resistance to chemical agents	Resistant to alcohol (70 %) Resistant to alcohol (96 %) Resistant to A-Lactic Acid Resistant to diluted quaternary ammonium Resistant to diluted bleach Resistant to diluted ammonia Resistant to soapy water Resistant to crystal cleaner Resistant to hydrogen peroxide 10 volumes Resistant to hexane

Environment

IK degree of protection	IK04
-------------------------	------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.9 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Width	17.8 cm
Package 1 Length	25.0 cm
Package 1 Weight	607.0 g
Unit Type of Package 2	S04
Number of Units in Package 2	14
Package 2 Height	30 cm
Package 2 Width	40 cm
Package 2 Length	60 cm
Package 2 Weight	9.271 kg
Unit Type of Package 3	P06
Number of Units in Package 3	56
Package 3 Height	80.0 cm
Package 3 Width	80.0 cm
Package 3 Length	60.0 cm
Package 3 Weight	45.668 kg

Contractual warranty

Warranty (in months)	18
----------------------	----



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)



Environmental footprint

Lower carbon footprint

3 kg CO2 eq.

Use Better



Materials and Substances

SCIP Number

Ce89f989-36a8-4890-9b3e-79150ca1abc2

EU RoHS Directive

[Compliant](#)

REACH Regulation

[Reference contains Substances of Very High Concern above the threshold](#)

Use Longer



Lifetime extension

Repair

No

Use Again



Repack and remanufacture

Take-back

No

WEEE Label



The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins