


## 997A.20 | MINI CROPPERS




### Description :

- Compact, lightweight tool with demultiplication system designed to cut hard and semi-hard wire: piano wire, bolts, rivets, pins and nails, etc.
- Forged, hardened blades.
- Cutting capacity: - Piano wire: max. diameter 2 mm to 200 kg/mm<sup>2</sup>. - Soft wire: max. diameter 4 mm to 60 kg/mm<sup>2</sup>.
- Ergonomic hardened pressed-steel handles with adjustable, shock-absorbing end stop.
- Spring-assisted opening.
- Blades lock in closed position.
- Finish: bronzed blades, painted grips.

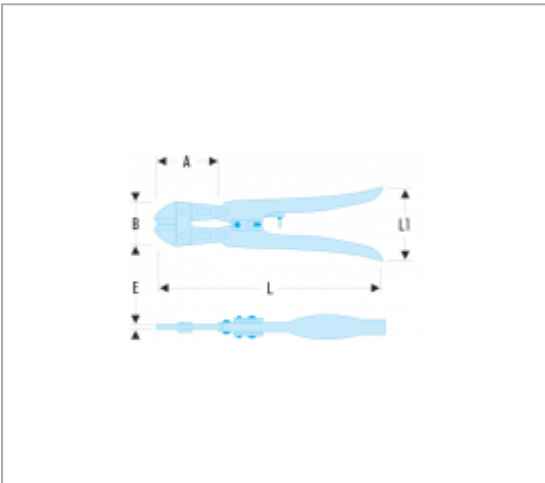

### Informations :

	997A.20
A [mm]	54,5
B [mm]	40
E [mm]	4,5
L [mm]	210
L1 [mm]	57
[g]	275