


PA-4000 120W AMPLIFIER

FEATURES

- Output power:
 - PA-2000 - 60Watts (RMS)
 - PA-4000 - 120Watts (RMS)
- Inputs: -6 balanced inputs with adjustable sensitivity
- XLR input connectors (CH 1-5), Phono (CH 6)
- Muting for Priority - Inputs 1and 2 Chime and Siren have automatic priority over inputs 3,4,5 & 6
- Telephone input has automatic priority over all other inputs
- 5 Band Equaliser (100Hz, 330Hz, 1KHz, 3,3KHz, 10KHz and 10dB
- 4 Tone Chime
- Remote Chime and Mute Control
- Speaker Selector: 5 individual speakers and all-call (100V/70V only)
- Link in/out jacks to enable additional amplifiers to be added

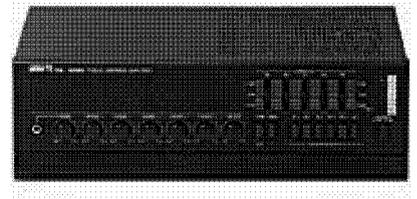

PART No.:	PA-4000
Rated Output	120W (RMS)
Frequency Response	60Hz - 20KHz
Total Harmonic Distortion	Less than 0.5%
Graphic Equalizer (100Hz, 330Hz, 1KHz, 3.3KHz, 10KHz)	± 12dB
Signal to Noise Ratio	105dB
Input Sensitivity/Impedance	
CH1 - CH6	0.25mV - 80mV/600ohm
Phono	2mV/22Kohm
Link In	100mV/15Kohm
Telephone In	0.775V/600ohm
Amp In	1V/47Kohm
Speaker Out/Impedance	22V/4ohm, 31V/8ohm, 70V/42ohm, 100V/83ohm
Link Out/Impedance	500mV/600ohm
Dimensions	420(W) x 132(H) x 320(D) mm
Net Weight	12kg

