


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearir
mm			kN		r/min		-
41,275	73,431	19,558	55	68	6700	10000	LM 501349/310/Q

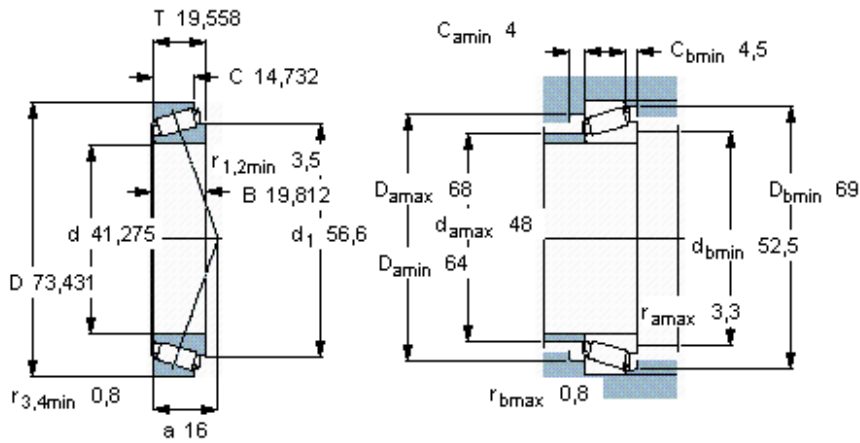

Calculation factors

e 0,4
 Y 1,5
 Y₀ 0,8