

Item code

# CDSHM 18



## Brief description:

male insert, 18 poles, Spring connection contacts SQUICH, 10A, 400V, silver plated, size "57.27", CLASS inserts

### Product description

<b>Model</b>	male insert
<b>Version</b>	Spring connection contacts SQUICH
<b>Series</b>	CDSH
<b>Product type</b>	with male contacts
<b>Family</b>	CLASS inserts
<b>Size</b>	size "57.27"
<b>N° of poles</b>	18 poles +
<b>Technical data</b>	
<b>Current</b>	10 A (A.C. and D.C.)
<b>Voltage</b>	400 V
<b>Sustained impulse voltage</b>	6kV
<b>Pollution degree</b>	3
<b>Wire section</b>	0,14 mm <sup>2</sup> - 2,50 mm <sup>2</sup>
<b>AWG size</b>	26 - 14
<b>Operating temperature range (min, max)</b>	-40°C ... +125°C
<b>Contact type</b>	silver plated
<b>Plugging cycles</b>	≥ 500
<b>IP degree of protection</b>	IP20 without enclosure; IP65/IP66/IP67/IP68 with enclosure
<b>Wire cross section PE</b>	0,14 - 4 mm <sup>2</sup> ; AWG 20 - 12
<b>Other technical details</b>	
<b>Insulation resistance</b>	≥ 10 GΩ
<b>Rated voltage according to UL/CSA</b>	
<b>Weight</b>	36,00 g

### Approvals / Standards

<b>Reference standard</b>	EN 61984 (2001-11)
<b>Quality mark</b>	UL, EAC
<b>Conformity</b>	CQC, CE

### General ordering information

<b>EAN code</b>	8015747222617
<b>Tariff number</b>	85369095

### Packaging Information

<b>Packaging length</b>	245,00 mm
<b>Packaging height</b>	165,00 mm
<b>Packaging width</b>	215,00 mm
<b>Packaging weight</b>	1,08 kg
<b>Packaging volume</b>	8,69 dm <sup>3</sup>
<b>Packaging description</b>	Carton box
<b>Packaging quantity</b>	30 Pcs
<b>Packaging EAN code</b>	8015747222778
<b>Sub-packaging length</b>	197,00 mm
<b>Sub-packaging height</b>	55,00 mm
<b>Sub-packaging width</b>	113,00 mm
<b>Sub-packaging weight</b>	0,18 kg
<b>Sub-packaging volume</b>	1,22 dm <sup>3</sup>
<b>Sub-packaging description</b>	Carton
<b>Sub-packaging quantity</b>	5 Pcs
<b>Sub-packaging EAN barcode</b>	8015747222785



Item code

# CDSHM 18



## Notes

actuator button connections

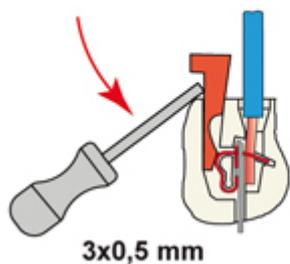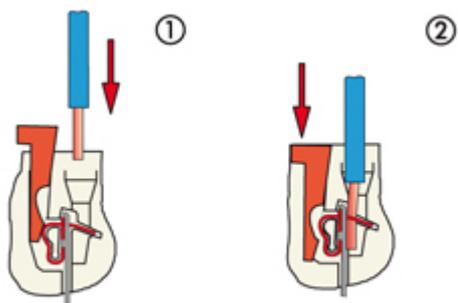

Reopening