


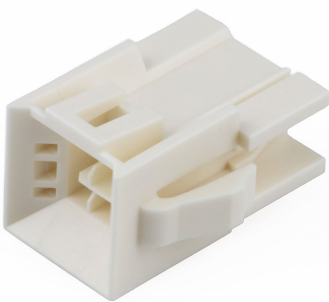

**Part Number :** [2245561410](#)  
**Product Description :** Nano-Fit BMI Plug Housing, TPA Capable, 2.50mm Pitch, Dual Row, 10 Circuits, Natural, Panel Mount, Glow-Wire Capable  
**Series Number :** 224556  
**Status :** Active  
**Product Category :** Connector Housings



## Documents & Resources

**Drawings**  
[2245561410\\_sd.pdf](#)  
[2245561000-PK-000.pdf](#)

**3D Models and Design Files**  
[2245561410\\_stp.zip](#)

**Specifications**  
[AS-105300-100-001.pdf](#)  
[2014471000-PS-000.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                |
|--------------------|------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                   |
| China RoHS         |                                                |
| EU ELV             | Not Relevant                                   |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21             |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024) |
| EU RoHS            | Compliant per EU 2015/863                      |

Multiple Part Product Compliance Statements  
- Eu RoHS  
- REACH SVHC  
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                                                                                                      |
|--------------|----------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                               |
| Category     | Connector Housings                                                                                                   |
| Series       | 224556                                                                                                               |
| Description  | Nano-Fit BMI Plug Housing, TPA Capable, 2.50mm Pitch, Dual Row, 10 Circuits, Natural, Panel Mount, Glow-Wire Capable |
| Application  | Power, Wire-to-Wire                                                                                                  |
| Product Name | Nano-Fit BMI                                                                                                         |
| UPC          | 196823687389                                                                                                         |

#### Physical

|                               |                |
|-------------------------------|----------------|
| Circuits (maximum)            | 10             |
| Color - Resin                 | Natural        |
| Gender                        | Plug           |
| Glow-Wire Capable             | Yes            |
| Keying to Mating Part         | Yes            |
| Lock to Mating Part           | Yes            |
| Material - Resin              | Nylon          |
| Net Weight                    | 2.310/g        |
| Number of Rows                | 2              |
| Packaging Type                | Bag            |
| Panel Mount                   | Yes            |
| Pitch - Mating Interface      | 2.50mm         |
| Pitch - Termination Interface | 2.50mm         |
| Polarized to Mating Part      | Yes            |
| Temperature Range - Operating | -40° to +125°C |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                               | Part Number       |
|-----------------------------------------------------------------------------------------------------------|-------------------|
| Nano-Fit Receptacle Housing, TPA Capable, 2.50mm Pitch, Dual Row, 10 Circuits, Natural, Glow-Wire Capable | <u>1053082210</u> |
| Nano-Fit BMI Receptacle Housing, 2.50mm Pitch, Dual Row, 10 Circuits, Natural, Glow-Wire Capable          | <u>2192682210</u> |

### Use with Part(s)

| Description                                          | Part Number   |
|------------------------------------------------------|---------------|
| Nano-Fit Male Crimp Terminals                        | <u>201447</u> |
| Nano-Fit Terminal Position Assurance (TPA) Retainers | <u>105325</u> |