

## GU10 LED ALL-GLASS DIMMERABILE

SLD620532D

4,6 W - 440lm - 3000K

25.000 H




40.000

INSTANT



DIMENSIONS	A	B	C
1	52	---	50

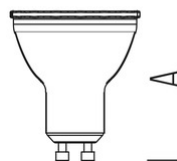

GENERAL INFORMATIONS	
Code	SLD620532D
Ean	8031453019761
Family	GU10 LED ALL-GLASS DIMMERABILE
Technology	LED
Energy class	A++
Operating temperature (° C)	-20 - +40

PACKAGING	
Packaging	BOX
Pack	10 / 100

LIGHTING DATA	
Kelvin (°)	3000
Lumen	440
Useful Lumen (lm)	400
Candela (cd)	750
Beam (°)	36
Luminous efficacy (lm / W)	95,65
Color rendering (CRI)	>80

TECHNICAL FEATURES	
Base	GU10
Power (W)	4,6
Equivalence (W)	50
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50/60
Power factor	>0,50
Dimmer compatibility	SI