



Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Accessories > Photo Control Cover



Lighting Product Type: **Cover**
Primary Product Color: **Natural**
Product Diameter: **76 mm [3 in]**
Lighting Connector Features Included: **Not Vented, Sleeve Compatible**

[All Photo Control Cover \(18\)](#)

Features

Product Type Features

Lighting Product Type	Cover
-----------------------	-------

Configuration Features

Lighting Connector Features Included	Not Vented, Sleeve Compatible
--------------------------------------	-------------------------------

Body Features

Primary Product Color	Natural
-----------------------	---------

Dimensions

Product Diameter	76 mm[3 in]
------------------	-------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold



EU REACH Regulation (EC) No. 1907/2006

Current ECHA Candidate List: JAN 2025
(247)
Candidate List Declared Against: JAN 2025
(247)
SVHC > Threshold:
UV-329 (.5% in 16981748073)

Article Safe Usage Statements:
Wash thoroughly after handling. Do not handle until all safety precautions have been read and understood. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



TE Part # 1-2213871-1
LIGHT CONTROLLER BASE ASSY,
76MM DIA,5POS



TE Part # 1-2213871-3
LIGHT CONTROLLER BASE ASSY,
76MM DIA,3POS

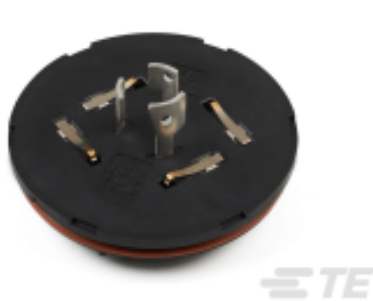

TE Part # 2213730-1
LIGHT CONTROLLER BASE
ASSEMBLY, 76MM DIA



TE Part # 1-2325661-1
LUMAWISE ENDURANCE N SHRTG
CAP BASE VENT



TE Part # 2325661-1
LUMAWISE ENDURANCE N SHRTNG
CAP BASE ASM



TE Part # 1-2336396-1
ASSEMBLY, LIGHT CONTROLLER
BASE, W/VENT



TE Part # 2213871-1
LIGHT CONTROLLER BASE ASSY,
76MM DIA,7POS

Also in the Series | LUMAWISE Endurance N



Street Lighting Accessories(18)




Street Lighting Base Assemblies(31)



Street Lighting Open & Shorting Caps
(3)



Street Lighting Power Management(6)

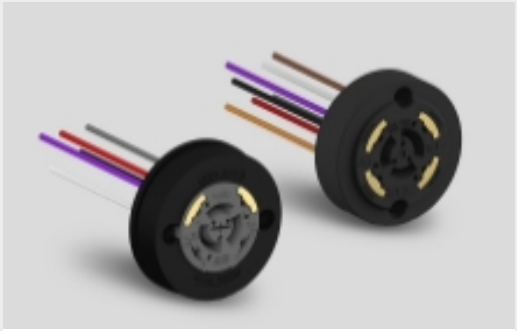

Street Lighting Receptacles(25)

Customers Also Bought



TE Part #2213627-3
ASSEMBLY, ROT DIM REC 49.22MM 5
POS 105C



TE Part #2314786-1
LUMAWISE N ENHANCED BASE, FM
ON, ZC YES




TE Part #CAT-ST833-P5663
Photo Control Cover



TE Part #1-2213871-2
LIGHT CONTROLLER BASE ASSY,
81MM DIA,5POS



TE Part #2213871-2
LIGHT CONTROLLER BASE ASSY,
81MM DIA,7POS

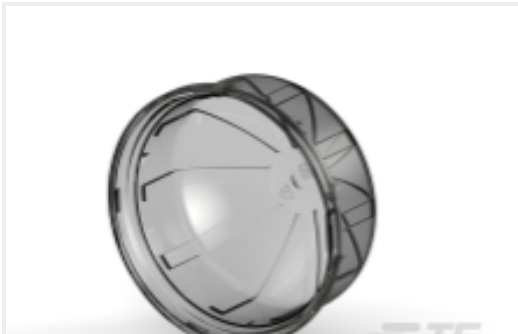

TE Part #2328823-2
LUMAWISE S 80MM DIA DOME
SMOKE GRAY MED



TE Part #1-2336396-2
ASSEMBLY, LIGHT CONTROLLER
BASE, W/VENT



TE Part #4515DO-DS3BK004GP
4IN PCB MOUNT I2C PRESSURE
SENSOR

Documents

Product Drawings
COVER, LIGHT CONTROL,76MM, CLEAR
English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_1-2213748-1_D.2d_dxf.zip



English

Customer View Model

ENG_CVM_CVM_1-2213748-1_D.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-2213748-1_D.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE

English

LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER

LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER

English

Photo Control Base and Cover flyer (Chinese)

English

Product Specifications

Application Specification

English

Agency Approvals

UL

English