


DATASHEET



GU5LDL

230V 5W GU10 LED 6000K

www.mlaccessories.co.uk

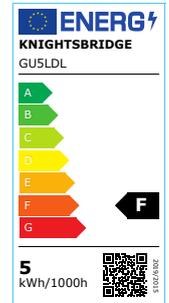

MLA PART CODE	GU5LDL
DESCRIPTION	230V 5W GU10 LED 6000K
NET WEIGHT (KG)	0.043
FINISH	White
DIFFUSER	Opal
DIMENSIONS (MM)	Diameter - 50 Height - 54
CONSTRUCTION	Construction - Aluminium Construction 2 - & polycarbonate
IP RATING	IP20
WATTAGE (W)	5
MAX. WATTAGE (W)	N/A
LAMP TECHNOLOGY	LED
LAMP BASE	GU10
LUMENS (LM)	430
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	87.97
CIRCUIT WATTAGE (W)	5.02
CCT	6000K
LIGHT COLOUR	Daylight
CRI	>80
SDCM	<6
RUNNING CURRENT (A)	0.04
DISPLACEMENT FACTOR	>0.9
SVM	0
PST-LM	0.02
BEAM ANGLE (DEGREES)	35
L70B50 LIFESPAN (HRS)	36,000
DIMMABLE	No
OPERATING TEMPERATURE	25°C

Knightsbridge

INPUT VOLTAGE	230V 50Hz
WARRANTY	2year(s)
MANUFACTURED IN ACCORDANCE WITH	BS EN 62560
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5055832991366

Date Created: 09/02/2022 11:50

