


AM102 – MAGNETIC MOUNT ANTENNA

1/4 Wave Multi-Band Micromag Antenna

Frequency: GSM850
 GSM900
 GSM1800
 GSM1900
 UMTS 2.1GHz (3G)
 Gain: 1.0dBi
 VSWR: Less than 2:1 in all bands
 Impedance: 50Ω

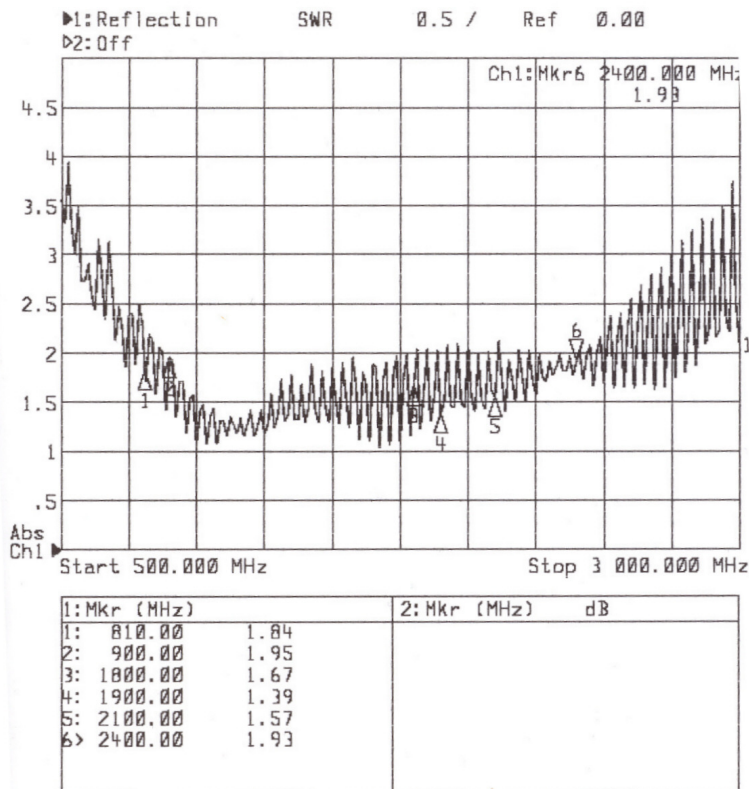

Physical Data

Gross Dimensions: 30mm dia. x 73mm Black over-mould base with brass whip.
 Mounting: Magnetic Mount
 Operating Temp: -40°C to +85°C
 Cable Length: 2.5m RG174 (-0mm, +100mm)
 Connectors: FME (f) Nickel-plated brass crimp type

The above data is to be used as baseline information only. For a more detailed specification, application support or application approval samples, please contact our technical support help desk on +44(0) 2392327 020. We reserve the right to modify the specifications without prior notice.