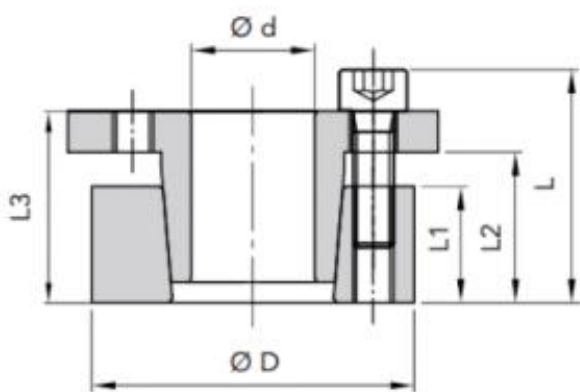


06160050

RCK 16 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06160050
Ød (DD) mm	50
ØD (D) mm	80
L1 (L1) mm	20
L2 (L2) mm	25
L3 (L3) mm	33
L (L) mm	41
Maximum torque Mt (MT) Nm	1820
Clamping pressure - Shaft (CPS) N/mm ²	195
Clamping pressure - Hub (CPH) N/mm ²	120
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	7
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x25
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Extraction thread - Type (ETT)	M8
Extraction thread - Num. (ETN)	3
Weight (WEIGHT) kg	0.80