


## SMD10-50AH

### Large Format Cable Slitter

Introducing the new SMD10-50AH Large Format Cable Slitter, a versatile tool cable of performing slit, ring, and spiral cuts on cable diameters from 10 to 50 mm. Equipped with a hardened steel blade, the tool provides fast, safe, and precise jacket removal from both hard and soft insulated cables without damaging the underlying layers.

### Features

- Equipped with safe, recessed blade to prevent potential injury & blade damage
- Compatible with large telecom cables, large fiber optic ducts & various other large diameter power cables
- Easily adjust the blade position to perform ring, spiral & longitudinal cuts
- Quickly adjusts to suit hard & soft insulated cables with 10 mm - 50mm diameters on cable ends & cable mid-spans
- Blade depth knob adjusts up to 4.5 mm in increments of 0.05 mm & features a convenient inch or metric scale for guaranteed precision
- Replaceable, machined & ground tool steel blade
- Reinforced diameter adjustment jaw is durable & travels on a threaded rod to provide precise stability between the blade & jacket
- Weight: 380 g      Dimensions: 79,1 X 38,2 X 148 mm.

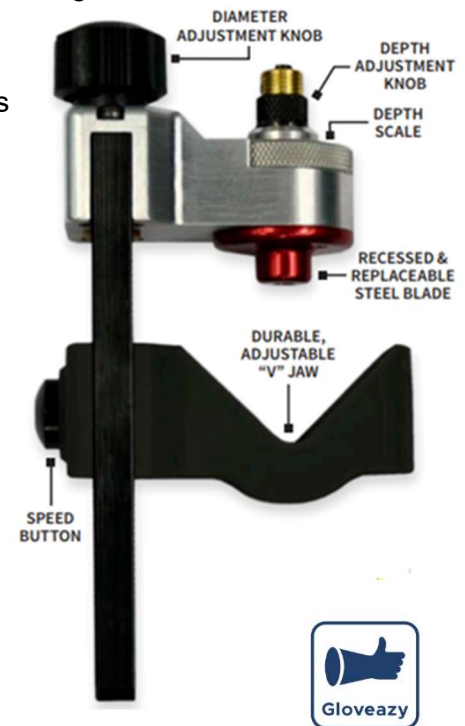

| CABLE DIAMETER | JACKET TYPES          | ADJUSTABLE BLADE DEPTH | REPLACEMENT BLADE PART |
|----------------|-----------------------|------------------------|------------------------|
| 10 to 50 mm    | HDPE-PE<br>PVC-Rubber | 4.5 mm                 | SMD10-50AHB            |



Ref. for tool with plastic case: **SMD10-50AHKC**



Quick-adjust jaw accepts hard & soft insulated cables ranging from 10 mm to 50 mm.



Knobs are engineered with knurls & grooves for easy adjustment when wearing gloves



Recessed steel blade makes tool safe to carry & store..



Quickly & easily performs ring, spiral & longitudinal cuts.