

# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Cable connector, series: CA, straight, shielded: yes, Screw locking mechanism, No. of pos. : 12, Direction of rotation: Counter direction, contact connection type: Socket, Crimp connection, cable diameter range: 6 mm ... 10 mm, coding: N, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1244523

## Commercial data

Item number	1622047
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	ABRAEA
GTIN	4055626004679
Weight per piece (including packing)	91.9 g
Weight per piece (excluding packing)	88.7 g
Customs tariff number	85366990
Country of origin	DE

# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

## Technical data

### Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

### Connector

Direction of rotation	Counter direction
-----------------------	-------------------

### Insulating body

Note	Order information: Order crimp contacts Ø 1 mm separately
Coding	N
Insulation body material	PA 6.6
Connection method	Crimp connection
Contact switching type	Socket
Application	Signal
Number of positions	12
Direction of rotation	Counter direction
Connection profile	12
Contact diameter	1 mm
<b>Power contacts</b>	
Rated current	8 A
Rated voltage	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

### Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

### Seal

External cable diameter	6 mm ... 10 mm
Seal material	NBR

## Environmental and real-life conditions

### Ambient conditions

Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

# CA-12S2N8A8007 - Cable connector


1622047

<https://www.phoenixcontact.com/in/products/1622047>



## Drawings

Schematic diagram

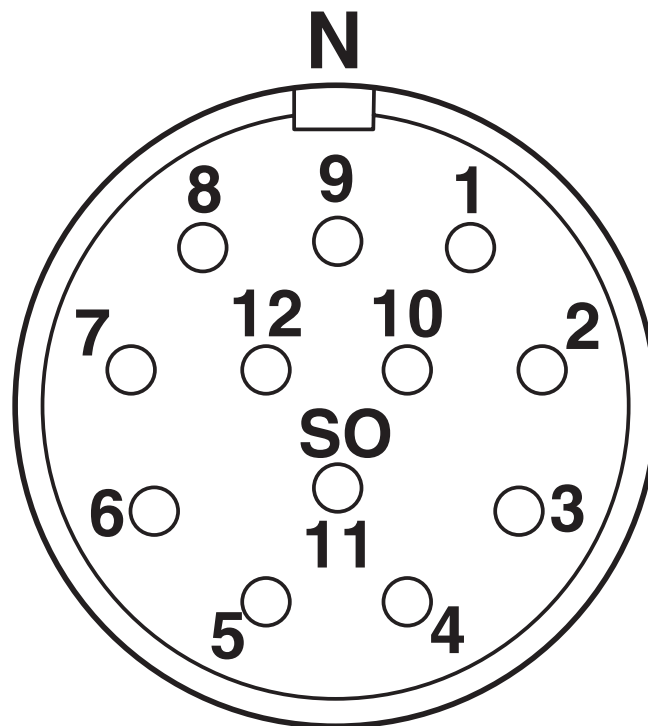

Contact chamber numbering (view of plug-in side), socket counter direction

# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1622047>

cUL Recognized Approval ID: E335019-20141210				
	Nominal voltage $U_N$	Nominal current $I_N$	Cross section AWG	Cross section $\text{mm}^2$
	48 V	4 A	20	-

UL Recognized Approval ID: E335019-20141210				
	Nominal voltage $U_N$	Nominal current $I_N$	Cross section AWG	Cross section $\text{mm}^2$
	48 V	6 A	20	-

cULus Recognized				
------------------	--	--	--	--

# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

## Classifications

### ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440116

### ETIM

ETIM 9.0	EC002635
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	173ad3f8-517c-4af6-9b96-5ee1bb862976

# CA-12S2N8A8007 - Cable connector

1622047

<https://www.phoenixcontact.com/in/products/1622047>



## Accessories

### CA-Z0077 - Metal protective cap

1627224

<https://www.phoenixcontact.com/in/products/1627224>



Metal protective cap, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1245447

---

### SF-Z0028 - Torque screwdriver

1607456

<https://www.phoenixcontact.com/in/products/1607456>



Torque screwdriver, series: RC, UC, SH, SF

## CA-12S2N8A8007 - Cable connector

1622047

<https://www.phoenixcontact.com/in/products/1622047>



## SF-Z0027 - Hook wrench

1607455

<https://www.phoenixcontact.com/in/products/1607455>



Hook wrench, series: RC, UC, RF, SF

---

## RF-Z0014 - Color coding

1620588

<https://www.phoenixcontact.com/in/products/1620588>

Color coding, color: green



# CA-12S2N8A8007 - Cable connector

1622047

<https://www.phoenixcontact.com/in/products/1622047>




## RF-Z0015 - Color coding

1620592

<https://www.phoenixcontact.com/in/products/1620592>

Color coding, color: orange

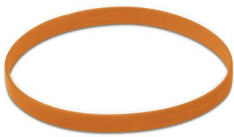

---

## RF-Z0016 - Color coding

1620593

<https://www.phoenixcontact.com/in/products/1620593>

Color coding, color: black



# CA-12S2N8A8007 - Cable connector



1622047

<https://www.phoenixcontact.com/in/products/1622047>

## RC-22S2000 - Crimp contact

1603327

<https://www.phoenixcontact.com/in/products/1603327>



Crimp contact, Socket, rolled, Single contact, contact diameter: 1 mm, crimp range: 0.22 mm<sup>2</sup> ... 0.56 mm<sup>2</sup>, Single contact, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

---

## RC-12S2000 - Crimp contact

1599600

<https://www.phoenixcontact.com/in/products/1599600>



Crimp contact, Socket, turned, Single contact, contact diameter: 1 mm, crimp range: 0.14 mm<sup>2</sup> ... 0.56 mm<sup>2</sup>, Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1241093

# CA-12S2N8A8007 - Cable connector

1622047

<https://www.phoenixcontact.com/in/products/1622047>



## RF-Z0003 - Square mounting flange

1607905

<https://www.phoenixcontact.com/in/products/1607905>



Square mounting flange, Axial seal, 4xM3, flange dimensions: 35 mm x 35 mm, series: RF, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1242369

---

## PROT-M23-SG-IT-IP20 - Plastic protective cap

1577206

<https://www.phoenixcontact.com/in/products/1577206>



Plastic protective cap, M23, series: CA, RC, RF, UC, RM

---

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)