

## HIGH RESISTANCE CEILING LIGHT GIADA


GIADA153

15,0 W - 1700lm - 4000K

IP65

50.000 H

NOT DIMMABLE

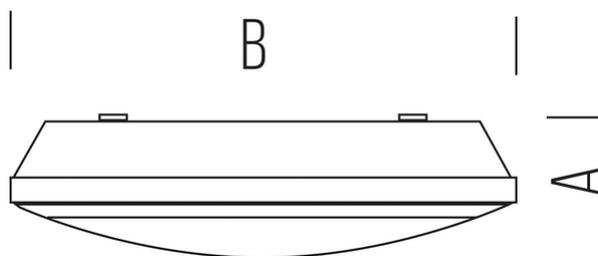

DIMENSIONS

1

### GENERAL INFORMATIONS

Code	GIADA153
Ean	8031453023645
Family	HIGH RESISTANCE CEILING LIGHT GIADA
Product line	plafoniera
Technology	LED
Variant	
Body material	PC
Diffuser / lens material	PC
Operating temperature (° C)	-20 - +40

### PACKAGING

Packaging	BOX
Pack	5

ACCESSORIES		
	GIADA ACCESSORIES	GIADAT0B
	GIADA ACCESSORIES	GIADAT1B
	GIADA ACCESSORIES	GIADAT1W
	GIADA ACCESSORIES	GIADAT2B
	GIADA ACCESSORIES	GIADAT2W

LIGHTING DATA	
Kelvin (°)	4000
Lumen	1700
Beam (°)	120
Luminous efficacy (lm / W)	113,33
Color rendering (CRI)	>80

TECHNICAL FEATURES	
Power (W)	15,0
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50/60
Insulation class	2
Power factor	>0,9
Dimmer compatibility	NO

## HIGH RESISTANCE CEILING LIGHT GIADA

GIADA153

15,0W - 1700lm - 4000K

- IK10 high resistance polycarbonate ceiling light
- High efficiency up to 115 lm/W
- Flicker-Free
- Lockable ring with vandal-proof Allen key, screen fixed with screws (not visible)
- Double input hole for in / out connection
- Predisposition for through connection on the sides
- Also available with 3h lasting emergency module at 150 lm
- Also available with microwave sensor programmable by dip-switch (sensitivity, ambient light level, duration)

Predisposto per terminali IP65  
optional (non inclusi)

IP65 connection terminal is  
optional (not included)



Fori posteriori per  
inserimento cavo loop in /  
loop out compatibile con  
connessioni da 68/78mm

Holes at the back side  
of housing for loop in/  
loop out. Compatible with  
68/78mm junction box

